


Stirrup Clamp

By ANDERSON
Catalog # [ACHLS13](#)

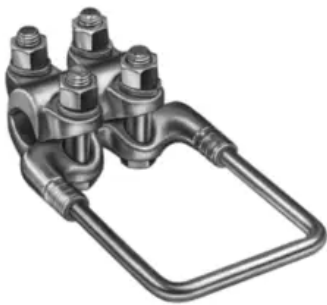

Aluminum alloy stirrup clamp for making temporary or permanent ground connections to aluminum tubing. The copper stirrup loop is tin plated and is compressed into the body casting.

Features

- For use with AAC and ACSR conductor.
- Conductor Diameter Range: 1.081-1.293 inches
- Conductor Range: 900 - 1250 MCM AAC and 715 - 1113 MCM ACSR
- Material: Castings - 356-T6 aluminum alloy, Stirrup - copper tin plated, Hardware - aluminum alloy
- Contact sealant is recommended.

General

Bolt Installation Torque (Recommended)	0 ft-lbs
Catalog Number	ACHLS13
EU RoHS Indicator	No
Material	Aluminum
Material - Hardware	Aluminum
Material - Stirrup	Copper, Tin Plated
UPC	096359280323

Dimensions

Weight	1.47 lb
--------	---------

Conductor Related

Conductor Compatibility	ACSR-Redwing-715.5-30/19;ACSR-Cuckoo-795-24/7;ACSR-Drake-795-26/7;ACSR-Conдор-795-54/7;ACSR-Mallard-795-30/19;ACSR-Ruddy-900-45/7;ACSR-Canary-900-54/7;ACSR-Rail-954-45/7;ACSR-Cardinal-954-
-------------------------	--

54/7;ACSR-Ortolan-1033.5-45/7;ACSR-Curlew-1033.5-54/7;ACSR-Bluejay-1113-45/7;ACSR-Finch-1113-54/19;AAC-Cockscomb-900-37;AAC-Snapdragon-900-61;AAC-Magnolia-954-37;AAC-Goldenrod-954-61;AAC-Camellia-1000-61;AAC-Bluebell-1033.5-37;AAC-Larkspur-1033.5-61;AAC-Marigold-1113-61;AAC-Hawthorn-1192.5-61

Conductor Diameter - Maximum	1.293 in
Conductor Diameter - Minimum	1.081 in
Conductor Diameter Range	1.081 - 1.293
Conductor Type	AAC, ACSR

Certifications And Compliance

Buy America(n) Qualified	TAA Compliant (All status valid till December 2024)
--------------------------	---

Logistics

Pallet Quantity	384
-----------------	-----

Product Assets

- [Sales Drawings - C-7854 \(ACHLS Product Family\)](#)
- [Specifications - ACHLS13](#)
- [Video - Hubbell Power Systems 3D Portal to help with developing 3D models of substation connector products](#)
- [Video - Hubbell Power Systems Quick Ship](#)