


# HUBBELL Power Systems

## Stirrup Clamp

By ANDERSON  
Catalog # [ACHLS16](#)

Aluminum alloy stirrup clamp for making temporary or permanent ground connections to aluminum tubing. The copper stirrup loop is tin plated and is compressed into the body casting.

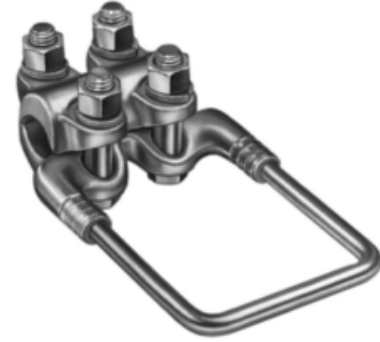

### Features

- For use with AAC and ACSR conductor.
- Conductor Diameter Range: 1.382 - 1.632 inches
- Conductor Range: 1500 - 2000 MCM AAC and 1272 (45/7) - 1590 (54/19) MCM ACSR
- Material: Castings - 356-T6 aluminum alloy, Stirrup - copper tin plated, Hardware - aluminum alloy
- Contact sealant is recommended.

### General

Bolt Installation Torque (Recommended)	0 ft-lbs
EU RoHS Indicator	No
Material	Aluminum
Material - Hardware	Aluminum
Material - Stirrup	Copper, Tin Plated
UPC	096359280330

### Dimensions

Weight	2.646 lb
--------	----------

### Conductor Related

Conductor Compatibility	ACSR-Pheasant-1272-54/19;ACSR-Dipper-1351.5-45/7;ACSR-Martin-1351.5-54/19;ACSR-Bobolink-1431-45/7;ACSR-Plover-1431-54/19;ACSR-Nuthatch-1510.5-45/7;ACSR-Parrot-1510.5-54/19;ACSR-Lapwing-1590-45/7;ACSR-Falcon-1590-54/19;ACSR-Chukar-1780-84/19;AAC-Gladiolus-1510.5-61;AAC-Coreopsis-1590-61;AAC-Cowslip-2000-91
Conductor Diameter - Maximum	1.632 in
Conductor Diameter - Minimum	1.382 in
Conductor Diameter Range	1.382 - 1.632
Conductor Type	AAC, ACSR

### Logistics

Pallet Quantity	270
-----------------	-----

### Product Assets

[Catalogs - Substation Connectors Combined Sales Drawings - C-7854 \(ACHLS Product Family\)](#)  
[Video - Hubbell Power Systems 3D Portal to help with developing 3D models of substation connector products](#)  
[Video - Hubbell Power Systems Quick Ship](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
AN-ACHLS16-SPEC-EN | REV 6/2024