


Stirrup Clamp

By ANDERSON
Catalog # [ACHLS21](#)

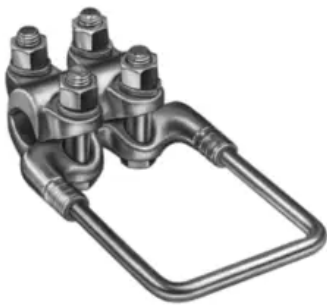

Aluminum alloy stirrup clamp for making temporary or permanent ground connections to aluminum tubing. The copper stirrup loop is tin plated and is compressed into the body casting.

Features

- For use with AAC condutor.
- Conductor Diameter Range: 1.824 - 2.000 inches
- Conductor Range: 2500 - 3000 MCM AAC
- Material: Castings - 356-T6 aluminum alloy, Stirrup - copper tin plated, Hardware - aluminum alloy
- Contact sealant is recommended.

General

Bolt Installation Torque (Recommended)	0 ft-lbs
Catalog Number	ACHLS21
EU RoHS Indicator	No
Material	Aluminum
Material - Hardware	Aluminum
Material - Stirrup	Copper, Tin Plated
UPC	096359280354

Dimensions

Weight	3.626 lb
--------	----------

Conductor Related

Conductor Compatibility	ACSR-Joree-2515-76/19
Conductor Diameter - Maximum	2 in
Conductor Diameter - Minimum	1.824 in
Conductor Diameter Range	1.824 - 2
Conductor Type	AAC, ACSR

Certifications And Compliance

Buy America(n) Qualified	Contact Manufacturer
--------------------------	----------------------

Logistics

Pallet Quantity	288
-----------------	-----

Product Assets

- [Sales Drawings - C-7854 \(ACHLS Product Family\)](#)
- [Specifications - ACHLS21](#)
- [Video - Hubbell Power Systems 3D Portal to help with developing 3D models of substation connector products](#)
- [Video - Hubbell Power Systems Quick Ship](#)