


HUBBELL

Power Systems

Deadend, Straight line, Stirrup Clamp, AAC, AAAC, ACAR, ACSR, Conductor Range 0.18 - 0.46 in, Fitting: None

By ANDERSON
Catalog # [ADES46N](#)

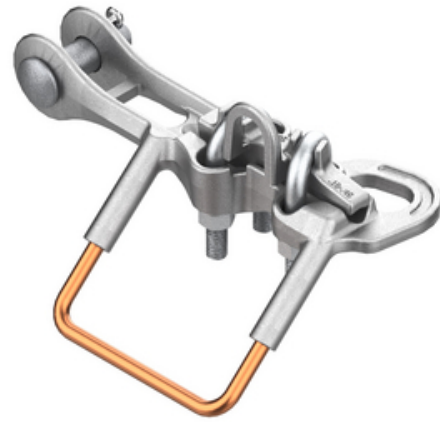

Deadend, Straight line, Stirrup Clamp, AAC, AAAC, ACAR, ACSR, Conductor Range 0.18 - 0.46 in, Fitting: None

Features

Add "S" for socket OR "C" for clevis fitting options

General

Fitting Type	None
Material	Aluminum
Material - Body	356 T6 Aluminum Alloy
Material - Hardware	Galvanized Steel
Material - Keeper	356 T6 Aluminum Alloy
Product Category	Straight Line
Strength Rating - Ultimate	6000 lb
Body	
Style	ADES
Type	Bolted
U-Bolts	2 in
UPC	096359281016

Dimensions

Clevis Opening	0.75 in
Diameter - Bolt	0.375 in
Diameter - Pin	0.625 in
Length	7.5 in
Take Up	0 in
Weight	1.8 lb
Width	0.75 in

Electrical Ratings

Voltage Application	Standard
---------------------	----------

Conductor Related

Conductor Compatibility	ACSR-Turkey-6-6/1;ACSR-Swan-4-6/1;ACSR-Sparrow-2-6/1;ACSR-Robin-1-6/1;ACSR-Raven-1/0-6/1;ACSR-Quail-2/0-6/1;AAC-Peachbell-6-7;AAC-Rose-4-7;AAC-Iris-2-7;AAC-Pansy-1-7;AAC-Poppy-1/0-7;AAC-Aster-2/0-7;AAAC 6201 Alloy-Akron-30.58-6/18;AAAC 6201 Alloy-Alton-48.69-6/18;AAAC 6201 Alloy-Ames-77.47-6/18;AAAC 6201 Alloy-Azusa-123.3-6/18;AAAC 6201 Alloy-Anaheim-155.4-6/18
Conductor Diameter - Maximum	0.46
Conductor Diameter - Minimum	0.18
Conductor Diameter Range	0.18 - 0.46

Logistics

Pallet Quantity	450
-----------------	-----

Product Assets

[Catalogs - Distribution Connectors](#)
[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Sales Drawings - Aluminum Dead-End Stirrup-Strain Clamp \(C-1689\)](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
AN-ADES46N-SPEC-EN | REV 6/2024