


Deadend, Straight line, Spring
Loaded, Side Opening, 350 (37
STR) - 1000 (61 STR) AL, 336.4
(18/1) - 954 (36/1) ACSR

By ANDERSON
Catalog # [ADEZ116N](#)

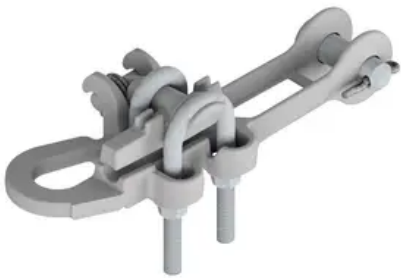

Deadend, Straight line, Spring Loaded, Side Opening, 350 (37 STR) - 1000 (61 STR) AL, 336.4 (18/1) - 954 (36/1) ACSR, Conductor Range 0.68 - 1.16 in, Fitting: None.

Features

- Captive hardware to prevent disassembly
- pivoting spring loaded keeper for easy conductor insertion
- Add "S" for Socket or "C" for Clevis Fitting Options

General

Catalog Number	ADEZ116N
Fitting Type	None
Material	Aluminum
Material - Body	356 T6 Aluminum Alloy
Material - Hardware	Galvanized Steel
Material - Keeper	356 T6 Aluminum Alloy
Material - Pin (Cotter)	Stainless Steel
Material - Socket and Clevis	Ductile Iron, Galvanized
Material - Spring (on Eyestem)	Stainless Steel
Product Category	Straight Line
Strength Rating - Ultimate	12000 lb
Body	
Style	ADEZ
Type	Bolted
U-Bolts	2 in
UPC	096359281092

Dimensions

Diameter - Bolt	0.5 in
Diameter - Pin	0.625 in
Length	10.81 in
Weight	3.7 lb
Width	1 in

Conductor Related

Conductor Compatibility	ACSR-Ostrich-300-26/7;ACSR-Merlin-336.4-18/1;ACSR-Linnet-336.4-26/7;ACSR-Oriole-336.4-30/7;ACSR-Chickadee-397.5-18/1;ACSR-Brant-397.5-24/7;ACSR-Ibis-397.5-26/7;ACSR-Lark-397.5-30/7;ACSR-Pelican-477-
-------------------------	--

18/1;ACSR-Flicker-477-24/7;ACSR-Hawk-477-26/7;ACSR-Hen-477-30/7;ACSR-Osprey-556.5-18/1;ACSR-Parakeet-556.5-24/7;ACSR-Dove-556.5-26/7;ACSR-Eagle-556.5-30/7;ACSR-Peacock-605-24/7;ACSR-Squab-605-26/7;ACSR-Teal-605-30/19;ACSR-Kingbird-636-18/1;ACSR-Swift-636-36/1;ACSR-Rook-636-24/7;ACSR-Grosbeak-636-26/7;ACSR-Egret-636-30/19;ACSR-Flamingo-666.6-24/7;ACSR-Gannet-666.6-26/7;ACSR-Stilt-715.5-24/7;ACSR-Starling-715.5-26/7;ACSR-Redwing-715.5-30/19;ACSR-Coot-795-36/1;ACSR-Cuckoo-795-24/7;ACSR-Drake-795-26/7;ACSR-Tern-795-45/7;ACSR-Condor-795-54/7;ACSR-Mallard-795-30/19;ACSR-Ruddy-900-45/7;ACSR-Brahma-203.2-16/19;AAC-Canna-397.5-19;AAC-Cosmos-477-19;AAC-Syringa-477-37;AAC-Zinnia-500-19;AAC-Hyacinth-500-37;AAC-Dahlia-556.5-19;AAC-Mistletoe-556.5-37;AAC-Meadowsweet-600-37;AAC-Orchid-636-37;AAC-Flag-700-61;AAC-Violet-715.5-37;AAC-Nasturtium-715.5-61;AAC-Cattail-750-61;AAC-Arbutus-795-37;AAC-Lilac-795-61;AAC-Cockscomb-900-37;AAC-

	Snapdragon-900-61;AAC-Magnolia-954-37;AAC-Goldenrod-954-61;AAC-Camellia-1000-61;ACAR-653.1-12/7;ACAR-739.8-18/19;ACAR-853.7-30/7
Conductor Diameter - Maximum	1.16
Conductor Diameter - Minimum	0.68
Conductor Diameter Range	0.68 - 1.16

Certifications And Compliance

Buy America(n) Qualified	TAA Compliant (All status valid till December 2024)
--------------------------	---

Logistics

Pallet Quantity	240
-----------------	-----

Product Assets

- Catalogs - Distribution Connectors
- Installation Manuals - ADEZ Series Aluminum Deadend
- Recommended Installation Instructions
- Literature - Deadends For Overhead Connections
- Literature - Ropes Course Industry Letter (April 2021)
- Sales Drawings - AL, DE Easy On Clamp FF # Adez-See Table
- Specifications - ADEZ116N

