


## Deadend, Straight line, Spring Loaded, Side Opening, #4 (7 STR) - 350 (19 STR) AL, #4 (6/1) - 336.4 (18/1) ACSR

By ANDERSON  
Catalog # [ADEZ70N](#)

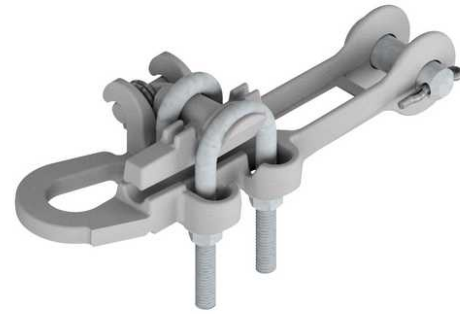

\*Representative Image

Deadend, Straight line, Spring Loaded, Side Opening, #4 (7 STR) - 350 (19 STR) AL, #4 (6/1) - 336.4 (18/1) ACSR, Conductor Range 0.31 - 0.70 in, Fitting: None.

### Features

- Captive hardware to prevent disassemblyPivoting spring loaded keeper for easy conductor insertionAdd "S" for Socket or "C" for Clevis Fitting Options

### General

Fitting Type	None
Material	Aluminum Alloy
Material - Body	356 T6 Aluminum Alloy
Material - Hardware	Galvanized Steel
Material - Keeper	356 T6 Aluminum Alloy
Material - Pin (Cotter)	Stainless Steel
Material - Socket and Clevis	Ductile Iron, Galvanized
Material - Spring (on Eystem)	Stainless Steel
Product Category	Straight Line
Strength Rating - Ultimate Body	9000 lb
Style	ADEZ
Type	Bolted
U-Bolts	2 in
UPC	096359612612

### Dimensions

Diameter - Bolt	0.375 in
Diameter - Pin	0.625 in
Length	8.250 in
Weight	1.600 lb
Width	0.937 in

### Conductor Related

Conductor Diameter - Maximum	0.7
Conductor Diameter - Minimum	0.31
Conductor Diameter Range	0.31 - 0.7
Conductor Type	<ul style="list-style-type: none"> <li>• AAC</li> <li>• ACSR</li> <li>• AAAC</li> </ul>

### Logistics

Pallet Quantity 800

### Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)  
[Installation Manuals - ADEZ Series Aluminum Deadend Recommended Installation Instructions](#)  
[Literature - Ropes Course Industry Letter \(April 2021\)](#)  
[Literature - Deadends For Overhead Connections \(LEEDS-HPS-DEADEND-QUICK-REFERENCE-GUIDE-SF-EN-2023\\_Web\)](#)  
[Sales Drawings - AL, DE Easy On Clamp FF # Adez-See Table \(CC-15659\)](#)

### Related Products

[ADEZ88N - Deadend, Straight line, Spring Loaded, Side Opening, 3/0 \(7 STR\) - 556 \(37 STR\) AL, 2/0 \(6/1\) - 556 \(18/1\) ACSR](#)  
[ADEZ116N - Deadend, Straight line, Spring Loaded, Side Opening, 350 \(37 STR\) - 1000 \(61 STR\) AL, 336.4 \(18/1\) - 954 \(36/1\) ACSR](#)  
[ADEZ47N - Deadend, Straight line, Spring Loaded, Side Opening, #4 \(7 STR\) - 3/0 \(7 STR\) AL, #6 \(6/1\) - 2/0 \(6/1\) ACSR](#)

