


Deadend, Straight line, 336.4 (19 STR) - 1272 (61 STR) AL, 266.8 (26/7) - 1192.5 (45/7) ACSR

By ANDERSON
Catalog # [ADS130N](#)

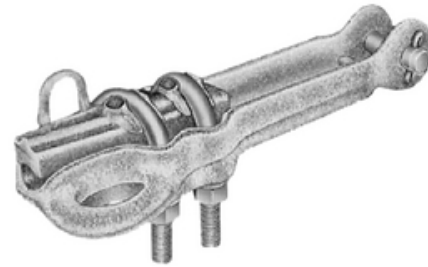

Deadend, Straight line, 336.4 (19 STR) - 1272 (61 STR) AL, 266.8 (26/7) - 1192.5 (45/7) ACSR, Conductor Range 0.64 - 1.3 in, Fitting: None.

*Representative Image

Features

- Add "S" for socket or "C" for Clevis fitting options, Extra length for greater insulator clearance
- Spring Loaded, side opening keeper for easy installation
- Single 1/2" U-Bolt for use with hand or hydraulic tool installation
- RUS Listed

General

Fitting Type	None
Material	Aluminum
Material - Body	356 T6 Aluminum Alloy
Material - Hardware	Galvanized Steel
Material - Keeper	356 T6 Aluminum Alloy
Material - Pin (Cotter)	#302 Stainless Steel
Product Category	Straight Line
Strength Rating - Ultimate Body	15000 lb
Style	ADS
Type	Bolted
U-Bolts	2
UPC	096359281344

Dimensions

Diameter - Bolt	0.500 in
Diameter - Pin	0.625 in
Length	10.500 in
Weight	3.000 lb
Width	1.000 in

Conductor Related

Conductor Compatibility	ACSR-Partridge-266.8-26/7;ACSR-Ostrich-300-26/7;ACSR-Merlin-336.4-18/1;ACSR-Linnet-336.4-26/7;ACSR-Oriole-336.4-30/7;ACSR-Chickadee-397.5-18/1;ACSR-Brant-397.5-24/7;ACSR-Ibis-397.5-26/7;ACSR-Lark-397.5-30/7;ACSR-Pelican-477-18/1;ACSR-Flicker-477-24/7;ACSR-Hawk-477-26/7;ACSR-Hen-477-30/7;ACSR-Osprey-556.5-18/1;ACSR-Parakeet-556.5-
-------------------------	---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------

18/1;ACSR-Canyon-1000-54/7;ACSR-Bluejay-1113-45/7;ACSR-Finch-1113-54/19;ACSR-Brahma-203.2-16/19;AAC-Daffodil-350-19;AAC-Canna-397.5-19;AAC-Cosmos-477-19;AAC-Syringa-477-37;AAC-Zinnia-500-19;AAC-Hyacinth-500-37;AAC-Dahlia-556.5-19;AAC-Mistletoe-556.5-37;AAC-Meadowsweet-600-37;AAC-Orchid-636-37;AAC-Flag-700-61;AAC-Violet-715.5-37;AAC-Nasturtium-715.5-61;AAC-Cattail-750-61;AAC-Arbutus-795-37;AAC-Lilac-795-61;AAC-Cockscomb-900-37;AAC-Snapdragon-900-61;AAC-Magnolia-954-37;AAC-Goldenrod-954-61;AAC-Camellia-1000-61;AAC-Bluebell-1033.5-37;AAC-Larkspur-1033.5-61;AAC-Marigold-1113-61;AAC-Hawthorn-1192.5-61;AAC-Narcissus-1272-61;ACAR-653.1-12/7;ACAR-739.8-18/19;ACAR-853.7-30/7;ACAR-1024.5-30/7;ACAR-1081-18/19;ACAR-1109-30/7;ACAR-1172-30/7;ACAR-1172-18/19;ACAR-1197-30/7

Conductor Diameter - Maximum	1.3 in
Conductor Diameter - Minimum	0.64 in
Conductor Diameter Range	0.64 - 1.3

Logistics

Pallet Quantity	480
-----------------	-----

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Literature - Deadends For Overhead Connections \(LEEDS-HPS-DEADEND-QUICK-REFERENCE-GUIDE-SF-EN-2023_Web\)](#)
[Sales Drawings - Deadend, Clamp \(C-8253\)](#)

Related Products

[ADS116N - Deadend, Straight line, #1 \(7 STR\) - 1000 \(61 STR\)](#)

18/7;ACSR-Parakeet-556.5-
24/7;ACSR-Dove-556.5-
26/7;ACSR-Eagle-556.5-
30/7;ACSR-Peacock-605-
24/7;ACSR-Squab-605-
26/7;ACSR-Teal-605-
30/19;ACSR-Kingbird-636-
18/1;ACSR-Swift-636-
36/1;ACSR-Rook-636-
24/7;ACSR-Grosbeak-636-
26/7;ACSR-Egret-636-
30/19;ACSR-Flamingo-666.6-
24/7;ACSR-Gannet-666.6-
26/7;ACSR-Stilt-715.5-
24/7;ACSR-Starling-715.5-
26/7;ACSR-Redwing-715.5-
30/19;ACSR-Coot-795-
36/1;ACSR-Cuckoo-795-
24/7;ACSR-Drake-795-
26/7;ACSR-Tern-795-
45/7;ACSR-Condor-795-
54/7;ACSR-Mallard-795-
30/19;ACSR-Ruddy-900-
45/7;ACSR-Canary-900-
54/7;ACSR-Rail-954-
45/7;ACSR-Cardinal-954-
54/7;ACSR-Ortolan-1033.5-
45/7;ACSR-Curlew-1033.5-

ACSR-Deadend, Straight line, #1 (7 STR) - 1800 (61 STR)
AL, #2 (6/1) - 954 (36/1) ACSR,
ADS155N - Deadend, Straight line, 397.5 (19 STR) - 1800 (127
STR) AL, 336.4 (26/7) - 1590.5 (54/19) ACSR



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
AN-ADS130N-SPEC-EN | REV 1/2024