


Deadend, Straight line, 397.5 (19 STR) - 1800 (127 STR) AL, 336.4 (26/7) - 1590.5 (54/19) ACSR

By ANDERSON
Catalog # [ADS155N](#)

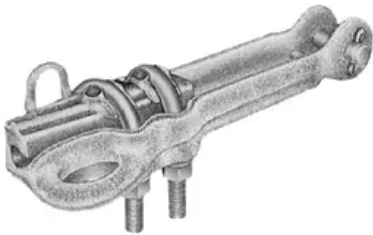

*Representative Image

Deadend, Straight line, 397.5 (19 STR) - 1800 (127 STR) AL, 336.4 (26/7) - 1590.5 (54/19) ACSR, Conductor Range 0.72 - 1.55 in, Fitting: None.

Features

- Add "S" for socket or "C" for Clevis fitting options, Extra length for greater insulator clearance
- Spring Loaded, side opening keeper for easy installation
- Single 1/2" U-Bolt for use with hand or hydraulic tool installation
- RUS Listed

General

Catalog Number	ADS155N
EU RoHS Indicator	Contact Manufacturer
Fitting Type	None
Material	Aluminum
Material - Body	356 T6 Aluminum Alloy
Material - Hardware	Galvanized Steel
Material - Keeper	356 T6 Aluminum Alloy
Material - Pin (Cotter)	#302 Stainless Steel
Product Category	Straight Line
Strength Rating - Ultimate	6000 lb
Body	
Style	ADSB
Type	Bolted
U-Bolts	2 in
UPC	096359281382

Dimensions

Diameter - Bolt	0.5 in
Diameter - Pin	0.625 in
Length	11.75 in
Weight	4.4 lb
Width	1 in

Conductor Related

Conductor Compatibility	ACSR-Linnet-336.4- 26/7;ACSR-Oriole-336.4- 30/7;ACSR-Chickadee-397.5- 18/1;ACSR-Brant-397.5- 24/7;ACSR-Ibis-397.5- 26/7;ACSR-Lark-397.5- 30/7;ACSR-Pelican-477-
-------------------------	---

18/1;ACSR-Flicker-477- 24/7;ACSR-Hawk-477- 26/7;ACSR-Hen-477- 30/7;ACSR-Osprey-556.5- 18/1;ACSR-Parakeet-556.5- 24/7;ACSR-Dove-556.5- 26/7;ACSR-Eagle-556.5- 30/7;ACSR-Peacock-605- 24/7;ACSR-Squab-605- 26/7;ACSR-Teal-605- 30/19;ACSR-Kingbird-636- 18/1;ACSR-Swift-636- 36/1;ACSR-Rook-636- 24/7;ACSR-Grosbeak-636- 26/7;ACSR-Egret-636- 30/19;ACSR-Flamingo-666.6- 24/7;ACSR-Gannet-666.6- 26/7;ACSR-Stilt-715.5- 24/7;ACSR-Starling-715.5- 26/7;ACSR-Redwing-715.5- 30/19;ACSR-Coot-795- 36/1;ACSR-Cuckoo-795- 24/7;ACSR-Drake-795- 26/7;ACSR-Tern-795- 45/7;ACSR-Condor-795- 54/7;ACSR-Mallard-795- 30/19;ACSR-Ruddy-900- 45/7;ACSR-Canary-900- 54/7;ACSR-Rail-954- 45/7;ACSR-Cardinal-954- 54/7;ACSR-Ortolan-1033.5- 45/7;ACSR-Curlew-1033.5- 54/7;ACSR-Bluejay-1113- 45/7;ACSR-Finch-1113- 54/19;ACSR-Bunting-1192.5- 45/7;ACSR-Grackle-1192.5- 54/19;ACSR-Bittern-1272- 45/7;ACSR-Pheasant-1272- 54/19;ACSR-Dipper-1351.5- 45/7;ACSR-Martin-1351.5- 54/19;ACSR-Bobolink-1431- 45/7;ACSR-Plover-1431-
--

54/19;ACSR-Nuthatch-1510.5-45/7;ACSR-Parrot-1510.5-54/19;ACSR-Lapwing-1590-45/7;ACSR-Falcon-1590-54/19;AAC-Canna-397.5-19;AAC-Cosmos-477-19;AAC-Syringa-477-37;AAC-Zinnia-500-19;AAC-Hyacinth-500-37;AAC-Dahlia-556.5-19;AAC-Mistletoe-556.5-37;AAC-Meadowsweet-600-37;AAC-Orchid-636-37;AAC-Flag-700-61;AAC-Violet-715.5-37;AAC-Nasturtium-715.5-61;AAC-Cattail-750-61;AAC-Arbutus-795-37;AAC-Lilac-795-61;AAC-Cockscomb-900-37;AAC-Snapdragon-900-61;AAC-Magnolia-954-37;AAC-Goldenrod-954-61;AAC-Camellia-1000-61;AAC-Bluebell-1033.5-37;AAC-Larkspur-1033.5-61;AAC-Marigold-1113-61;AAC-Hawthorn-1192.5-61;AAC-Narcissus-1272-61;AAC-Columbine-1351.5-61;AAC-Carnation-1431-61;AAC-Gladiolus-1510.5-61;AAC-Coreopsis-1590-61;ACAR-653.1-12/7;ACAR-739.8-18/19;ACAR-853.7-30/7;ACAR-1024.5-30/7;ACAR-1081-18/19;ACAR-1109-30/7;ACAR-1172-30/7;ACAR-1172-18/19;ACAR-1197-30/7		
Conductor Diameter - Maximum		1.55
Conductor Diameter - Minimum		0.72
Conductor Diameter Range		0.72 - 1.55
Certifications And Compliance		
Buy America(n) Qualified		TAA Compliant (All status valid till December 2024)
Logistics		
Pallet Quantity		320
Product Assets		
Catalogs - Distribution Connectors		
Literature - Deadends For Overhead Connections		
Literature - Ropes Course Industry Letter (April 2021)		
Sales Drawings - Deadend, Clamp (C-8253)		
Specifications - ADS155N		



A Hubbell brand