


Deadend, Straight line, #4 (7 STR) - 266.8 (19 STR) AL, #6 (6/1) - 266.8 (18/1) ACSR

By ANDERSON
Catalog # [ADS60N](#)

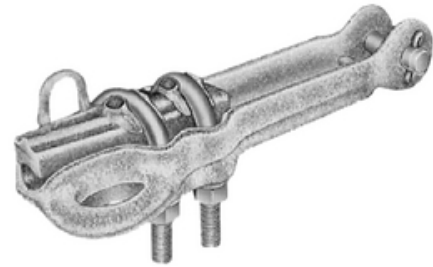

*Representative Image

Deadend, Straight line, #4 (7 STR) - 266.8 (19 STR) AL, #6 (6/1) - 266.8 (18/1) ACSR, Conductor Range 0.19 - 0.6 in, Fitting: None.

Features

- Add "S" for socket or "C" for Clevis fitting options, Extra length for greater insulator clearance
- Spring Loaded, side opening keeper for easy installation
- Single 1/2" U-Bolt for use with hand or hydraulic tool installation
- RUS Listed

General

Fitting Type	None
Material	Aluminum
Material - Body	356 T6 Aluminum Alloy
Material - Hardware	Galvanized Steel
Material - Keeper	356 T6 Aluminum Alloy
Material - Pin (Cotter)	#302 Stainless Steel
Product Category	Straight Line
Strength Rating - Ultimate Body	7000 lb
Style	ADS - Long
Type	Bolted
U-Bolts	2 in
UPC	096359281467

Dimensions

Diameter - Bolt	0.5 in
Diameter - Pin	0.625 in
Length	8.250 in
Weight	2.000 lb
Width	0.750 in

Conductor Related

Conductor Compatibility	ACSR-Turkey-6-6/1;ACSR-Swan-4-6/1;ACSR-Sparrow-2-6/1;ACSR-Robin-1-6/1;ACSR-Raven-1/0-6/1;ACSR-Quail-2/0-6/1;ACSR-Pigeon-3/0-6/1;AAC-Rose-4-7;AAC-Iris-2-7;AAC-Pansy-1-7;AAC-Poppy-1/0-7;AAC-Aster-2/0-7;AAC-Phlox-3/0-7;AAC-Oxlip-4/0-7;AAC-Valerian-250-19;AAC-Laurel-266.8-19;AAAC 6201 Alloy-Akron-30.58-6/18;AAAC 6201 Alloy-Alton-48.69-6/18;AAAC 6201 Alloy-Ames-77.47-6/18;AAAC 6201 Alloy-Azusa-123.3-6/18;AAAC 6201 Alloy-Anaheim-155.4-6/18;AAAC 6201 Alloy-Amherst-195.7-6/18;AAAC 6201 Alloy-Alliance-246.9-6/18
Conductor Diameter - Maximum	0.6
Conductor Diameter - Minimum	0.19
Conductor Diameter Range	0.19 - 0.6

Logistics

Pallet Quantity	960
-----------------	-----

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Literature - Deadends For Overhead Connections \(LEEDS-HPS-DEADEND-QUICK-REFERENCE-GUIDE-SF-EN-2023_Web\)](#)
[Sales Drawings - Deadend, Clamp \(C-8253\)](#)

Related Products

[ADS48N - Deadend, Straight line, #6 \(7 STR\) - 3/0 \(19 STR\) AL, #6 \(6/1\) - 3/0 \(6/1\) ACSR](#)
[ADS60LN - Deadend, Straight line, #4 \(7 STR\) - 266.8 \(19 STR\) AL, #6 \(6/1\) - 266.8 \(18/1\) ACSR](#)

