


Stirrup Clamp

By ANDERSON
Catalog # [AHL5024021E](#)

Overhead Stirrup, Bolted, Stirrup, Aluminum,
AAC|AAAC|ACSR, Range 0.325 - 0.563 in

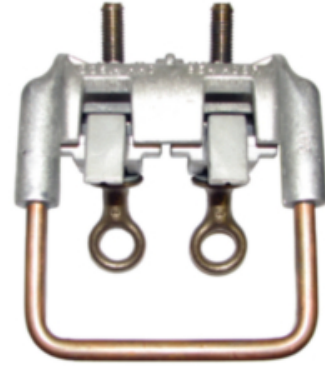

*Representative Image

Features

- Easy hotstick installation, Peened thread to prevent disassembly.

General

Hot Stick Eyes	Yes
Inhibitor Loaded	No
Material	Aluminum Alloy
Material - Bail	Copper
Material - Body	Aluminum
Material - Eystem	Stainless Steel
Material - Keeper	Aluminum Alloy
Material - Spring (on Eystem)	Stainless Steel
Material - Stirrup	Copper
Material - Washer	Stainless Steel
Number of Eyebolts	2
Plating	No
Type	Stirrups
UPC	096359282853

Dimensions

Copper Loop Size	0.325 in
Diameter - Bolt	0.375 in
Diameter - Stirrup Nominal Wire	1/0 Solid
Dimensions	4.590 in x 2.920 in x 5.000 in
Height	5.000 in
Length	4.590 in
Weight	1.274 lb
Width	2.920 in
Width - Main Contact	3.5 in

Conductor Related

Conductor Compatibility	ACSR-Turkey-6-6/1;ACSR-Swan-4-6/1;ACSR-Swanate-4-7/1;ACSR-Sparrow-2-6/1;ACSR-Sparate-2-7/1;ACSR-Robin-1-6/1;ACSR-Raven-1/0-6/1;ACSR-Quail-2/0-6/1;ACSR-Pigeon-3/0-6/1;ACSR-Penguin-4/0-6/1;AAC-Peachbell-6-7;AAC-Rose-4-7;AAC-Iris-2-7;AAC-Pansy-1-7;AAC-Poppy-1/0-7;AAC-Aster-2/0-7;AAC-Phlox-3/0-7;AAC-Oxlip-4/0-7;AAAC 6201 Alloy-Akron-30.58-6/18;AAAC 6201 Alloy-Alton-48.69-6/18;AAAC 6201 Alloy-Ames-77.47-6/18;AAAC 6201 Alloy-Azusa-123.3-6/18;AAAC 6201 Alloy-Anaheim-155.4-6/18;AAAC 6201 Alloy-Amherst-195.7-6/18
Conductor Diameter - Maximum	0.563
Conductor Diameter - Minimum	0.325
Conductor Diameter Range	0.325 - 0.563
Conductor Type	Aluminum

Logistics

Packaging Type	Box
Pallet Quantity	1200

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Sales Drawings - C-4409](#)

[Video - Hubbell Power Systems In Depth: Stirrup Clamps \(VI05101E\)](#)

[Video - Hubbell Power Systems Hotline Tap Clamps and Stirrup Clamps \(VI05051E0919\)](#)

