


HUBBELL

Power Systems

Deadend, Straight line, Spring Loaded, Side opening, #4 (7 STR) - 4/0 (19 STR) AL, #6 (6/1) - 4/0 (6/1) ACSR

By ANDERSON
Catalog # [ASOD5701N](#)

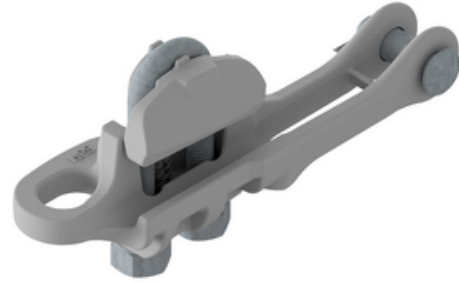

Deadend, Straight line, Spring Loaded, Side opening, #4 (7 STR) - 4/0 (19 STR) AL, #6 (6/1) - 4/0 (6/1) ACSR, Conductor Range 0.19 - 0.57 in, Fitting: None.

Features

Spring Loaded Vertical Keeper for Easy Installation, Add "S" for socket or "C" for clevis fitting options

General

Fitting Type	None
Material	Aluminum Alloy; Steel
Material - Body	356 T6 Aluminum Alloy
Material - Bolt	Galvanized Steel
Material - Hardware	Galvanized Steel
Material - Keeper	356 T6 Aluminum Alloy
Product Category	Straight Line
Strength Rating - Ultimate	8000 lb
Body	
Style	ASOD
Type	Bolted
U-Bolts	1
UPC	096359363347

Dimensions

Diameter - Bolt	0.5 in
Diameter - Pin	0.625 in
Length	8.62 in
Weight	1.95 lb
Width	0.7 in

Conductor Related

Conductor Diameter - Maximum	0.57
Conductor Diameter - Minimum	0.19
Conductor Diameter Range	0.19 - 0.57

Logistics

Pallet Quantity 600

Product Assets

[Catalog Page - ASOD Catalog Page](#)
[Catalogs - Distribution Connectors](#)
[Installation Manuals - ASOD_install instructions](#)
[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Literature - Deadends For Overhead Connections](#)
[Sales Drawings - AL, Side Opening Deadend Clamp \(CC-17236\)](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
AN-ASOD5701N-SPEC-EN | REV 6/2024