

**Deadend, Straight line, Spring
Loaded, Side opening, #2 (7 STR) -
556.5 (37 STR) AL, #4 (6/1) - 556.5
(18/1) ACSR**

By ANDERSON
Catalog # [ASOD8581N](#)

Deadend, Straight line, Spring Loaded, Side opening, #2 (7 STR)
- 556.5 (37 STR) AL, #4 (6/1) - 556.5 (18/1) ACSR, Conductor
Range 0.25 - 0.89 in, Fitting: None.

Features


- Spring Loaded Vertical Keeper for Easy Installation
- Add "S" for socket or "C" for clevis fitting options

General

Catalog Number	ASOD8581N
Fitting Type	None
Material	Aluminum Alloy; Steel
Material - Body	357 T6 Aluminum Alloy
Material - Bolt	Galvanized Steel
Material - Hardware	Galvanized Steel
Material - Keeper	357 T6 Aluminum Alloy
Product Category	Straight Line
Strength Rating - Ultimate	8000 lb
Body	
Style	ASOD
Type	Bolted
U-Bolts	1
UPC	096359396604

Dimensions

Diameter - Bolt	0.5 in
Diameter - Pin	0.625 in
Length	9.62 in

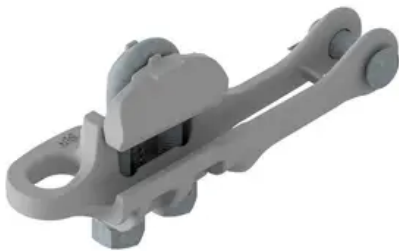

*Representative Image

Weight	2.4 lb
Width	0.7 in

Conductor Related

Conductor Diameter - Maximum	0.89
Conductor Diameter - Minimum	0.25
Conductor Diameter Range	0.25 - 0.89

Certifications And Compliance

Buy America(n) Qualified	TAA Compliant (All status valid till December 2024)
--------------------------	---

Logistics

Pallet Quantity	450
-----------------	-----

Product Assets

[Catalog Page - ASOD Catalog Page](#)
[Catalogs - Distribution Connectors](#)
[Installation Manuals - ASOD_install instructions](#)
[Literature - Deadends For Overhead Connections](#)
[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Sales Drawings - AL, Side Opening Deadend Clamp \(CC-17236\)](#)
[Specifications - ASOD8581N](#)