


## Deadend, Straight line, Spring Loaded, Side opening, 4/0 (7 STR) - 556.5 (37 STR) AL, 3/0 (6/1) - 556.5 (18/1) ACSR

By ANDERSON  
Catalog # [ASOD8582N](#)

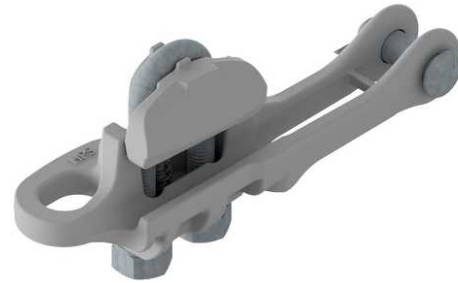

\*Representative Image

Deadend, Straight line, Spring Loaded, Side opening, 4/0 (7 STR) - 556.5 (37 STR) AL, 3/0 (6/1) - 556.5 (18/1) ACSR, Conductor Range 0.50 - 0.89 in, Fitting: None.

### Features

- Spring Loaded Vertical Keeper for Easy Installation
- Add "S" for socket or "C" for clevis fitting options

### General

Fitting Type	None
Material	Aluminum Alloy; Steel
Material - Body	356 T6 Aluminum Alloy
Material - Bolt	Galvanized Steel
Material - Hardware	Galvanized Steel
Material - Keeper	356 T6 Aluminum Alloy
Product Category	Straight Line
Strength Rating - Ultimate Body	12000 lb
Style	ASOD
Type	Bolted
U-Bolts	2
UPC	096359363651

### Dimensions

Diameter - Bolt	0.5 in
Diameter - Pin	0.625 in
Length	13.500 in
Weight	4.070 lb
Width	0.700 in

### Conductor Related

Conductor Diameter - Maximum	0.89
Conductor Diameter - Minimum	0.5
Conductor Diameter Range	0.5 - 0.89

### Logistics

Pallet Quantity	480
-----------------	-----

### Product Assets

[Catalog Page - ASOD Catalog Page](#)  
[Catalogs - Distribution Connectors \(CA05127E\)](#)  
[Installation Manuals - ASOD\\_install instructions](#)  
[Literature - Ropes Course Industry Letter \(April 2021\)](#)  
[Literature - Deadends For Overhead Connections \(LEEDS-HPS-DEADEND-QUICK-REFERENCE-GUIDE-SF-EN-2023\\_Web\)](#)  
[Sales Drawings - AL, Side Opening Deadend Clamp \(CC-17236\)](#)

### Related Products

[ASOD8581N - Deadend, Straight line, Spring Loaded, Side opening, #2 \(7 STR\) - 556.5 \(37 STR\) AL, #4 \(6/1\) - 556.5 \(18/1\) ACSR](#)  
[ASOD11602N - Deadend, Straight line, Spring Loaded, Side opening, 350 \(37 str\) - 954 \(61 str\) AL, 336.4 \(18/1\) - 900 \(54/7\) ACSR](#)