


HUBBELL

Power Systems

Compression Splice Full Tension

By ANDERSON
Catalog # [FTA795](#)

Full Tension Aluminum splice for 750 - 800 (37 or 61 STR) AAC

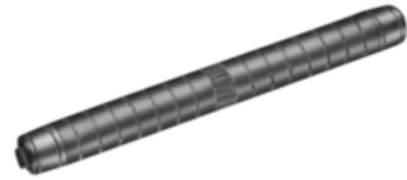

*Representative Image

Features

Has positive center stop and tapered ends.

General

Catalog Number	FTA795
Compression Method	Conventional Die Tooling
Die Size	Burndy 342
EU RoHS Indicator	Contact Manufacturer
Inhibitor Loaded	Yes
Material	Aluminum Alloy
UPC	096359303848

Dimensions

Length Before Compression	13.62 in
Weight	1.96 lb

Conductor Related

Conductor Compatibility	AAC-Cattail-750-61;AAC-Arbutus-795-37;AAC-Lilac-795-61;AAC-Snapdragon-900-61
Conductor Diameter - Maximum	1.031
Conductor Diameter - Minimum	0.998
Conductor Diameter Range	0.998 - 1.031

Certifications And Compliance

UL Listed	No
-----------	----

Logistics

Pallet Quantity	600
-----------------	-----

Product Assets

[Catalogs - Distribution Connectors](#)



A Hubbell brand