


Grounding Clamp

By ANDERSON
Catalog # [GC10301](#)

"Grounding Clamp, Bronze Bolted, Copper One, Two, or Three Cable to Rod or Tube Parallel, U-bolt style, Cables Dia. Range 0.574"-0.813" to 4" OD Rod or 3-1/2" EHIPS Tube, Material: Casting-Bronze alloy, Hardware-Silicon Bronze or Stainless steel"

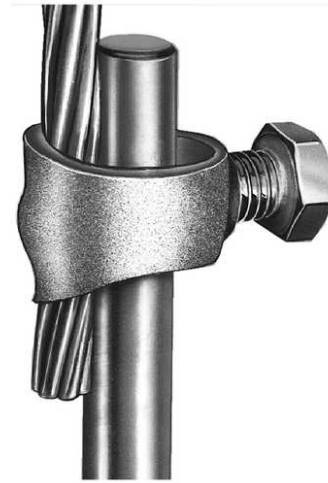

*Representative Image

Features

- "High pressure application
- Everdur hardware supplied by adding Suffix "ED"
e.g.GC10301ED"

General

EU RoHS Indicator	No
Material	Bronze
Material - Hardware	Stainless Steel
UPC	096359305361

Dimensions

Diameter - Rod Outside	0.5 in
Weight	0.196 lb

Conductor Related

Conductor Diameter - Maximum	0.414 in
Conductor Diameter - Minimum	0.204 in
Conductor Diameter Range	0.204 - 0.414
Conductor Type	Copper

Logistics

Pallet Quantity	3456
-----------------	------

Product Assets

[Sales Drawings - C-813 \(GC103 Product Family\)](#)

[Video - Hubbell Power Systems 3D Portal to help with developing 3D models of substation connector products \(VI05050E0619\)](#)

[Video - Hubbell Power Systems Quick Ship \(VI05124E1018\)](#)