


Grounding Clamp

By ANDERSON
Catalog # [GC11111C](#)

"Grounding Clamp, Bronze Bolted, Copper Cable to Rod or Tube, U-bolt style, Cables Range 0.365"-0.575" dia. to 1-3/4" OD Rod or 1-1/4" EHIPS Tube, Material: Casting-Bronze alloy, Hardware-Silicon Bronze or Stainless steel"

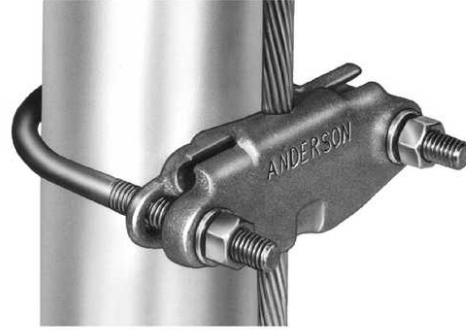

*Representative Image

Features

- "Everdur hardware supplied by adding Suffix ED"

General

EU RoHS Indicator	No
Material	Bronze
Material - Hardware	Stainless Steel
UPC	096359305774

Dimensions

Diameter - Clamping Hardware	4 in
Diameter - Rod / Tube	4 in
Diameter - Rod / Tube Outside	4.5 in
Weight	3.136 lb

Conductor Related

Conductor Diameter - Maximum	0.575 in
Conductor Diameter - Minimum	0.365 in
Conductor Diameter Range	0.365 - 0.575
Conductor Type	Copper

Logistics

Pallet Quantity	360
-----------------	-----

Product Assets

[Sales Drawings - C-2951 \(GC111 Product Family\)](#)

[Video - Hubbell Power Systems 3D Portal to help with developing 3D models of substation connector products \(VI05050E0619\)](#)

[Video - Hubbell Power Systems Quick Ship \(VI05124E1018\)](#)