


Grounding Clamp

By ANDERSON
Catalog # [GC11111D](#)

"Grounding Clamp, Bronze Bolted, Copper Cable to Rod or Tube, U-bolt style, Cables Range 0.365"-0.575" dia. to 1-3/4" OD Rod or 1-1/4" EHIPS Tube, Material: Casting-Bronze alloy, Hardware-Silicon Bronze or Stainless steel"

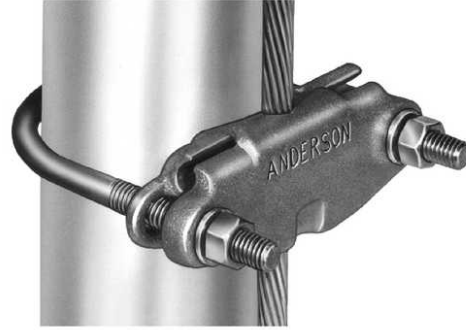

*Representative Image

Features

- "Everdur hardware supplied by adding Suffix ED"

General

EU RoHS Indicator	No
Material	Bronze
Material - Hardware	Stainless Steel
UPC	096359476740

Dimensions

Diameter - Clamping Hardware	4 in
Diameter - Rod / Tube	4 in
Diameter - Rod / Tube Outside	4.5 in
Weight	5.194 lb

Conductor Related

Conductor Diameter - Maximum	0.813 in
Conductor Diameter - Minimum	0.574 in
Conductor Diameter Range	0.574 - 0.813
Conductor Type	Copper

Product Assets

[Sales Drawings - C-2951 \(GC111 Product Family\)](#)

[Video - Hubbell Power Systems 3D Portal to help with developing 3D models of substation connector products \(VI05050E0619\)](#)

[Video - Hubbell Power Systems Quick Ship \(VI05124E1018\)](#)