


## Grounding Clamp

By ANDERSON  
Catalog # [GC11114C](#)

"Grounding Clamp, Bronze Bolted, Copper Cable to Rod or Tube, U-bolt style, Cables Range 0.204"-0.419" dia. to 2" OD Rod or 1-1/2" EHIPS Tube, Material: Casting-Bronze alloy, Hardware-Silicon Bronze or Stainless steel"

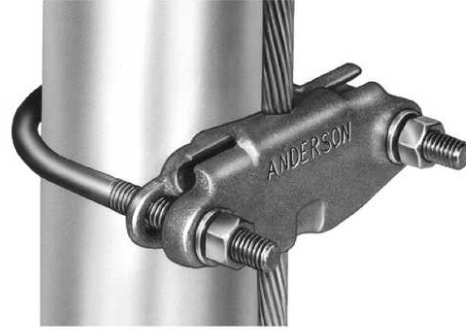

\*Representative Image

### Features

- "Everdur hardware supplied by adding Suffix ED"

### General

Material	Bronze
Material - Hardware	Stainless Steel
UPC	096359305811

### Dimensions

Diameter - Clamping Hardware	6 in
Diameter - Rod / Tube	6 in
Diameter - Rod / Tube Outside	6.625 in
Weight	6.037 lb

### Conductor Related

Conductor Diameter - Maximum	0.575 in
Conductor Diameter - Minimum	0.365 in
Conductor Diameter Range	0.365 - 0.575
Conductor Type	Copper

### Logistics

Pallet Quantity	252
-----------------	-----

### Product Assets

[Video - Hubbell Power Systems 3D Portal to help with developing 3D models of substation connector products \(VI05050E0619\)](#)

[Video - Hubbell Power Systems Quick Ship \(VI05124E1018\)](#)