


## Grounding Clamp

By ANDERSON  
Catalog # [GC1113A](#)

"Grounding Clamp, Bronze Bolted, Copper Cable to Rod or Tube, U-bolt style, Cables Range 0.204"-0.419" dia. to 2-1/2" OD Rod or 2" EHIPS Tube, Material: Casting-Bronze alloy, Hardware-Silicon Bronze or Stainless steel"

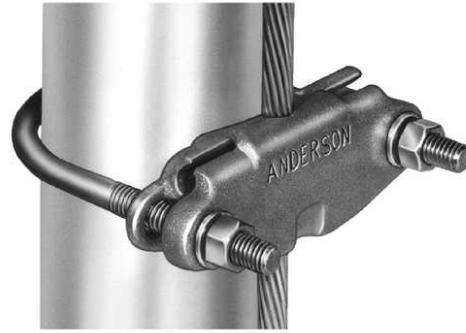

\*Representative Image

### Features

- "Everdur hardware supplied by adding Suffix ED"

### General

EU RoHS Indicator	No
Material	Bronze
Material - Hardware	Stainless Steel
UPC	096359305866

### Dimensions

Weight	0.490 lb
--------	----------

### Conductor Related

Conductor Diameter - Maximum	0.232 in
Conductor Diameter - Minimum	0.128 in
Conductor Diameter Range	0.128 - 0.232
Conductor Type	Copper

### Product Assets

[Sales Drawings - C-2951 \(GC111 Product Family\)](#)

[Video - Hubbell Power Systems 3D Portal to help with developing 3D models of substation connector products \(VI05050E0619\)](#)

[Video - Hubbell Power Systems Quick Ship \(VI05124E1018\)](#)