


Grounding Clamp

By ANDERSON
Catalog # [GC1115C](#)

"Grounding Clamp, Bronze Bolted, Copper Cable to Cable, Cross Connector, U-bolt style, Cable Range Main 2/0 Sol.-250 MCM, Tap #4 Sol.-2/0 Str, Material: Casting-Bronze alloy, Hardware-silicon bronze or stainless steel"

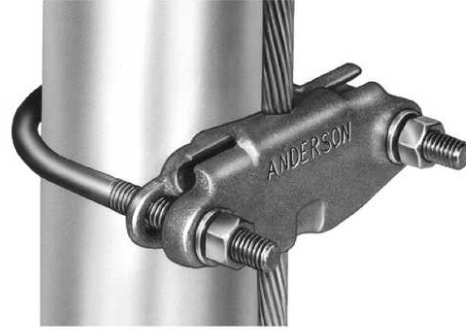

*Representative Image

Features

- "Everdur hardware supplied by adding Suffix ED"

General

Material	Bronze
Material - Hardware	Stainless Steel
UPC	096359305989

Dimensions

Diameter - Clamping Hardware	1.25 in
Diameter - Rod / Tube	1.25 in
Diameter - Rod / Tube Outside	1.75 in
Weight	1.568 lb

Conductor Related

Conductor Diameter - Maximum	0.575 in
Conductor Diameter - Minimum	0.365 in
Conductor Diameter Range	0.365 - 0.575
Conductor Type	Copper

Logistics

Pallet Quantity	1440
-----------------	------

Product Assets

[Video - Hubbell Power Systems 3D Portal to help with developing 3D models of substation connector products \(VI05050E0619\)](#)

[Video - Hubbell Power Systems Quick Ship \(VI05124E1018\)](#)