


Grounding Clamp

By ANDERSON
Catalog # [GC1116C](#)

"Grounding Clamp, Bronze Bolted, Copper Two Parallel Cables to Rod or Tube Perpendicular, U-bolt style, Cables Range 0.365"-0.575" dia. to 4-1/2" OD Rod or 4" EHIPS Tube, Material: Casting-Bronze alloy, Hardware-Silicon Bronze or Stainless steel"

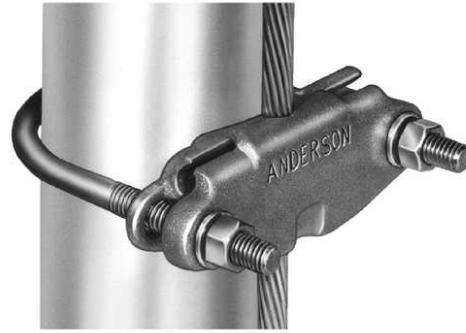

*Representative Image

Features

- "Everdur hardware supplied by adding Suffix ED"

General

Material	Bronze
Material - Hardware	Stainless Steel
UPC	096359306030

Dimensions

Diameter - Clamping Hardware	1.5 in
Diameter - Rod / Tube	1.5 in
Diameter - Rod / Tube Outside	2 in
Dimensions	1.875 in x 3.625 in x 4.5 in
Height	4.5 in
Length	1.875 in
Weight	1.607 lb
Width	3.625 in

Conductor Related

Conductor Diameter - Maximum	0.575 in
Conductor Diameter - Minimum	0.365 in
Conductor Diameter Range	0.365 - 0.575
Conductor Type	Copper

Logistics

Pallet Quantity	1050
-----------------	------

Product Assets

[Catalogs - Substation Connectors Combined \(CA05044E\)](#)
[Sales Drawings - C-2951 \(GC111 Product Family\)](#)

[Video - Hubbell Power Systems 3D Portal to help with developing 3D models of substation connector products \(VI05050E0619\)](#)

[Video - Hubbell Power Systems Quick Ship \(VI05124E1018\)](#)