


## Grounding Clamp

By ANDERSON  
Catalog # [GC1117B](#)

"Grounding Clamp, Bronze Bolted, Copper Two Parallel Cables to Rod or Tube Perpendicular, U-bolt style, Cables Range 0.128"-0.232" dia. to 5/8"-1" OD Rod or 3/8"-3/4" EHIPS Tube, Material: Casting-Bronze alloy, Hardware-Silicon Bronze or Stainless steel"

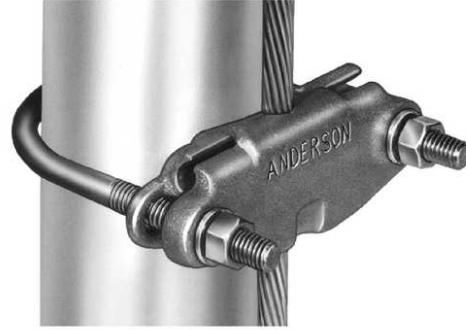

\*Representative Image

### Features

- "Everdur hardware supplied by adding Suffix ED"

### General

Material	Bronze
Material - Hardware	Stainless Steel
UPC	096359306061

### Dimensions

Diameter - Clamping Hardware	2 in
Diameter - Rod / Tube	2 in
Diameter - Rod / Tube Outside	2.5 in
Weight	1.274 lb

### Conductor Related

Conductor Diameter - Maximum	0.419 in
Conductor Diameter - Minimum	0.204 in
Conductor Diameter Range	0.204 - 0.419
Conductor Type	Copper

### Logistics

Pallet Quantity	756
-----------------	-----

### Product Assets

[Catalogs - Substation Connectors Combined \(CA05044E\)](#)

[Video - Hubbell Power Systems 3D Portal to help with developing 3D models of substation connector products \(VI05050E0619\)](#)

[Video - Hubbell Power Systems Quick Ship \(VI05124E1018\)](#)