


## Compression Stirrup

By ANDERSON  
Catalog # [HLS2662P](#)

Aluminum Overhead Compression Stirrup

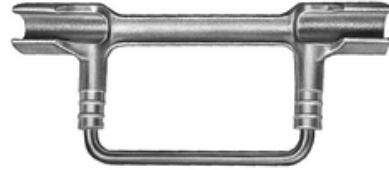

\*Representative Image

### Features

- Protects primary lines from arcing damage. Wide stance gives good stability for installing hotline clamp.

### General

Compression Tool Type	EEl-13A, 1-1/8
EU RoHS Indicator	No
Material	Aluminum Alloy
Material - Bail	Copper
Material - Body	Aluminum Alloy
Material - Stirrup	Copper
Plating	No
Type	Stirrups
UPC	096359316435

### Dimensions

Copper Loop Size	0.258 in
Diameter - Stirrup Nominal Wire	#2 Solid
Height	3.250 in
Weight	0.588 lb
Width - Main Contact	4 in

### Conductor Related

Conductor Compatibility	ACSR-Swan-4-6/1;ACSR-Swanate-4-7/1;ACSR-Sparrow-2-6/1;ACSR-Penguin-4/0-6/1;ACSR-Waxwing-266.8-18/1;AAC-Iris-2-7;AAC-Oxlip-4/0-7;AAC-Valerian-250-19;AAC-Laurel-266.8-19;AAAC 6201 Alloy-Alton-48.69-6/18;AAAC 6201 Alloy-Ames-77.47-6/18;AAAC 6201 Alloy-Alliance-246.9-6/18
Conductor Diameter - Maximum	0.609
Conductor Diameter - Minimum	0.522
Conductor Diameter Range	0.522 - 0.609
Conductor Type	Aluminum

### Logistics

Packaging Type	Bag
Pallet Quantity	1200

### Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)  
[Sales Drawings - CC-19211](#)  
[Technical Solutions - AN-HLS2662P-SPEC-EN](#)