


Compression Stirrup

By ANDERSON
Catalog # [HLS302P](#)

Aluminum Overhead Compression Stirrup

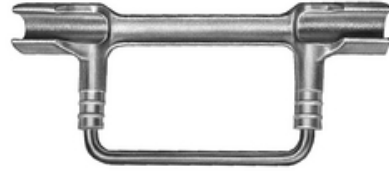

*Representative Image

Features

- Protects primary lines from arcing damage. Wide stance gives good stability for installing hotline clamp.

General

Compression Tool Type	EEl-13A, 1-1/8
EU RoHS Indicator	No
Material	Aluminum Alloy
Material - Bail	Copper
Material - Body	Aluminum Alloy
Material - Stirrup	Copper
Plating	No
Type	Stirrups
UPC	096359316442

Dimensions

Copper Loop Size	0.258 in
Diameter - Stirrup Nominal Wire	#2 Solid
Height	3.250 in
Weight	0.588 lb
Width - Main Contact	4 in

Conductor Related

Conductor Compatibility	ACSR-Turkey-6-6/1;ACSR-Quail-2/0-6/1;ACSR-Pigeon-3/0-6/1;AAC-Peachbell-6-7;AAC-Rose-4-7;AAC-Aster-2/0-7;AAC-Phlox-3/0-7;AAAC 6201 Alloy-Akron-30.58-6/18;AAAC 6201 Alloy-Anaheim-155.4-6/18;AAAC 6201 Alloy-Amherst-195.7-6/18
Conductor Diameter - Maximum	0.517
Conductor Diameter - Minimum	0.414
Conductor Diameter Range	0.414 - 0.517
Conductor Type	Aluminum

Logistics

Packaging Type	Bag
Pallet Quantity	1200

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Sales Drawings - CC-19211](#)
[Technical Solutions - AN-HLS302P-SPEC-EN](#)