


HUBBELL Power Systems

Connector, Parallel Groove

By ANDERSON
Catalog # K3

Two bolt Bronze Parallel Groove Connector

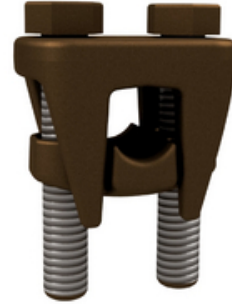

*Representative Image

Features

Has no cable separator.

General

Bolt Head Type	Hex
Bolt Installation Torque (Recommended)	0 ft-lbs
Cover Available	No
Inhibitor Loaded	No
Item Type	4D
Material	Bronze
Material - Body	Bronze Alloy
Material - Body Halves	Bronze Alloy
Material - Bolt	Silicon Bronze
Material - Bottom Member	Bronze Alloy
Material - Hardware	Silicon Bronze
Material - Spacer	Bronze Alloy
Plated	N
Plating	No
Plating Type	Unplated
Product Category	Mechanical Connectors
Style	Two Bolt
UPC	096359318583
UPC 12 Digit	781810291443

Dimensions

Bolt Diameter	0.38
Diameter - Bolt	0.38 in
Dimension - Hole Size mm	0 mm
Dimensions	1.125 in x 1.750 in x 1.938 in
Height	1.938 in
Length	1.125 in
Weight	0.4 lb
Width	1.75 in

Conductor Related

Conductor Diameter (Tap) - Maximum	0.528 in
Conductor Diameter (Tap) - Minimum	0.128 in
Conductor Diameter - Maximum	0.528
Conductor Diameter - Minimum	0.328
Conductor Diameter Range	0.328 - 0.528

Certifications And Compliance

Standards - RoHS Compliance Status	UI
UL Listed	No

Logistics

Pallet Quantity	5600
-----------------	------

Product Assets

[Catalogs - Distribution Connectors](#)
[Sales Drawings - C-1363](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
AN-K3-SPEC-EN | REV 6/2024