


## Deadend, Straight Line. Ductile, Copper, Copperweld, Alumoweld Conductor Range 0.18 - 0.46 in, Fitting: None.

By ANDERSON  
Catalog # [MDE46N](#)

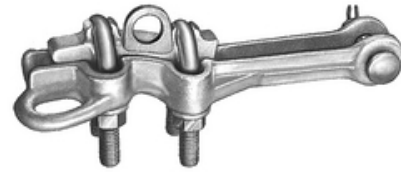

Deadend, Straight Line. Ductile, Copper, Copperweld, Alumoweld Conductor Range 0.18 - 0.46 in, Fitting: None.

\*Representative Image

### Features

- For use with copper and CopperWeld phase conductor
- Magnetic induction heating will occur
- For dead ending static wire
- Add "S" for socket OR "C" for clevis fitting

### General

Fitting Type	None
Material	Ductile Iron; Steel
Material - Body	Ductile Iron
Material - Hardware	Galvanized Steel
Material - Keeper	Ductile Iron
Product Category	Straight Line
Strength Rating - Ultimate Body	6000 lb
Style	MDE
Type	Bolted
U-Bolts	2 in
UPC	096359321927

### Dimensions

Clevis Opening	0.75 in
Diameter - Bolt	0.375 in
Diameter - Pin	0.625 in
Length	7.500 in
Weight	2.50 lb
Width	0.750 in

### Electrical Ratings

Voltage Application	Standard
---------------------	----------

### Conductor Related

Conductor Compatibility	ACSR-Turkey-6-6/1;ACSR-Swan-4-6/1;ACSR-Sparrow-2-6/1;ACSR-Robin-1-6/1;ACSR-Raven-1/0-6/1;ACSR-Quail-2/0-6/1;AAC-Peachbell-6-7;AAC-Rose-4-7;AAC-Iris-2-7;AAC-Pansy-1-7;AAC-Poppy-1/0-7;AAC-Aster-2/0-7;AAAC 6201 Alloy-Akron-30.58-6/18;AAAC 6201 Alloy-Alton-48.69-6/18;AAAC 6201 Alloy-Ames-77.47-6/18;AAAC 6201 Alloy-Azusa-123.3-6/18;AAAC 6201 Alloy-Anaheim-155.4-6/18
Conductor Diameter - Maximum	0.46
Conductor Diameter - Minimum	0.18
Conductor Diameter Range	0.18 - 0.46

### Logistics

Pallet Quantity	540
-----------------	-----

### Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)  
[Literature - Ropes Course Industry Letter \(April 2021\)](#)  
[Sales Drawings - C-5212](#)

### Related Products

[MDE60N - Deadend, Straight Line. Ductile, Copper, Copperweld, Alumoweld Conductor Range 0.36 - 0.60 in, Fitting: None.](#)

[MDE40N - Deadend, Straight Line. Ductile, Copper, Copperweld, Alumoweld Conductor Range 0.16 - 0.40 in, Fitting: None.](#)

