


Connector, Split Bolt, #2-2/0

By ANDERSON
Catalog # [SBS20](#)

Copper Split Bolt Connector.

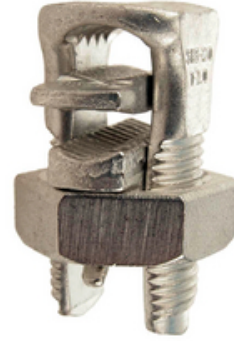

Features

- Has cable separator included.

General

Bolt Head Type	Hex
Item Type	4D
Material	Copper
Material - Body	Copper Alloy
Material - Spacer	Copper Alloy
Plating Type	Unplated
Product Category	Mechanical Connectors
Style	Split Bolt
UPC	096359373728
UPC 12 Digit	963593737282

Dimensions

Dimensions	1.040 in x 0.875 in x 1.950 in
Height	1.950 in
Length	1.040 in
Weight	0.210 lb
Width	0.875 in

Conductor Related

Conductor Diameter (Main) - Maximum	0.419 in
Conductor Diameter (Main) - Minimum	0.292 in
Conductor Diameter (Main) - Range	0.292 - 0.419
Conductor Diameter (Tap) - Maximum	0.419 in
Conductor Diameter (Tap) - Minimum	0.146 in

Certifications and Compliance

Certification - CSA Approved	Yes
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Pallet Quantity	9600 EA
-----------------	---------

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Sales Drawings - 10111020](#)