


# HUBBELL

## Power Systems

### Compression Splice VERSAtile™ Minimum Tension

By ANDERSON  
Catalog # [VACS1](#)

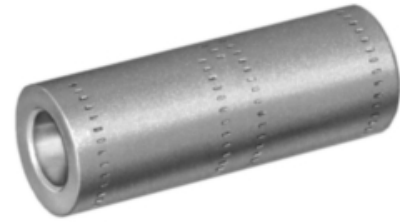

Minimum Tension versatile Compression Splice for #1/0 str  
AL/CU

\*Representative Image

#### Features

For AL to AL, AL to CU or CU to CU connections.

#### General

Catalog Number	VACS1
Color Code	Tan
Compression Method	VersaCrimp or Conventional
Die Tooling	Die Tooling
Die Size	*See Resources / Downloads for die selection and installation instructions
EU RoHS Indicator	Contact Manufacturer
Material	Aluminum Alloy
UPC	096359334323

#### Dimensions

Diameter - Inside	0.35 in
Weight	0.049 lb

#### Conductor Related

Conductor Compatibility	ACSR-Swan-4-6/1;ACSR-Swanate-4-7/1;ACSR-Sparrow-2-6/1;ACSR-Sparate-2-7/1;AAC-Rose-4-7;AAC-Iris-2-7;AAC-Pansy-1-7;AAAC 6201 Alloy-Alton-48.69-6/18;AAAC 6201 Alloy-Ames-77.47-6/18
Conductor Diameter (VersaCrimp) - Maximum	0.332 in
Conductor Diameter (VersaCrimp) - Minimum	0.232 in

#### Certifications And Compliance

UL Listed	Yes
-----------	-----

#### Logistics

Carton Quantity	250
-----------------	-----

#### Product Assets

- [Catalogs - Distribution Connectors](#)
- [Installation Manuals - VACS Splice Installation Instructions](#)
- [Sales Drawings - VACS\\_sales\\_drawing](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
AN-VACSI-SPEC-EN | REV 6/2024