


HUBBELL Power Systems

Compression Splice VERSAtile™ Minimum Tension

By ANDERSON
Catalog # [VACS10](#)

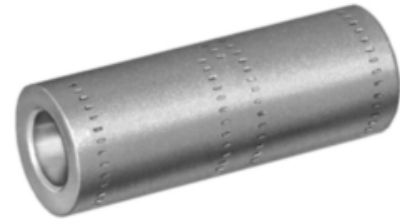

Minimum Tension versatile Compression Splice for 1/0 str AL/CU

*Representative Image

Features

- For AL to AL, AL to CU connections
- AL9CU (90°C Rated)
- UL Listed
- CSA Certified

General

Catalog Number	VACS10
Color Code	Tan
Compression Method	VersaCrimp or Conventional Die Tooling
Die Size	*See Resources / Downloads for die selection and installation instructions
EU RoHS Indicator	Contact Manufacturer
Material	Aluminum Alloy
UPC	096359334330

Dimensions

Diameter - Inside	0.393 in
Weight	0.098 lb

Conductor Related

Conductor Compatibility	ACSR-Turkey-6-6/1;ACSR-Swan-4-6/1;ACSR-Swanate-4-7/1;ACSR-Sparrow-2-6/1;ACSR-Sparate-2-7/1;ACSR-Robin-1-6/1;AAC-Peachbell-6-7;AAC-Rose-4-7;AAC-Iris-2-7;AAC-Pansy-1-7;AAC-Phlox-3/0-7;AAAC 6201 Alloy-Akron-30.58-6/18;AAAC 6201 Alloy-Alton-48.69-6/18;AAAC 6201 Alloy-Ames-77.47-6/18
-------------------------	---

Certifications And Compliance

UL Listed	Yes
-----------	-----

Logistics

Carton Quantity	150
-----------------	-----

Product Assets

[Catalogs - Distribution Connectors](#)
[Installation Manuals - VACS Splice Installation Instructions](#)
[Sales Drawings - VACS_sales_drawing](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
AN-VACS10-SPEC-EN | REV 6/2024