


HUBBELL Power Systems

Compression Splice VERSAtile™ Minimum Tension

By ANDERSON
Catalog # [VACS2](#)

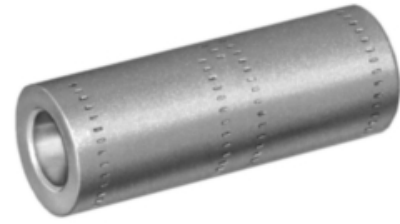

Minimum Tension versatile Compression Splice for #2 str AL/CU

*Representative Image

Features

- For AL to AL, AL to CU connections
- AL9CU (90°C Rated)
- UL Listed
- CSA Certified

General

Catalog Number	VACS2
Color Code	Pink
Compression Method	VersaCrimp or Conventional Die Tooling
Die Size	*See Resources / Downloads for die selection and installation instructions
EU RoHS Indicator	Contact Manufacturer
Material	Aluminum Alloy
UPC	096359334354

Dimensions

Diameter - Inside	0.312 in
Weight	0.029 lb

Conductor Related

Conductor Compatibility	ACSR-Turkey-6-6/1;ACSR- Swan-4-6/1;ACSR-Swanate-4- 7/1;AAC-Peachbell-6-7;AAC- Rose-4-7;AAC-Iris-2-7;AAAC 6201 Alloy-Akron-30.58- 6/18;AAAC 6201 Alloy-Alton- 48.69-6/18
-------------------------	---

Certifications And Compliance

UL Listed	Yes
-----------	-----

Logistics

Carton Quantity	250
-----------------	-----

Product Assets

[Catalogs - Distribution Connectors](#)
[Installation Manuals - VACS Splice Installation Instructions](#)
[Sales Drawings - VACS_sales_drawing](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
AN-VACS2-SPEC-EN | REV 6/2024