


HUBBELL Power Systems

Compression Splice VERSAtile™ Minimum Tension

By ANDERSON
Catalog # [VACS350](#)

Minimum Tension versatile Compression Splice for 350 MCM str
AL/CU

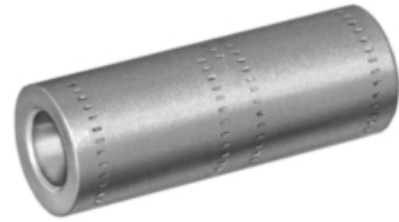

*Representative Image

Features

- For AL to AL, AL to CU connections
- AL9CU (90°C Rated)
- UL Listed
- CSA Certified

General

Catalog Number	VACS350
Color Code	Brown
Compression Method	VersaCrimp or Conventional Die Tooling
Die Size	*See Resources / Downloads for die selection and installation instructions
EU RoHS Indicator	Contact Manufacturer
Material	Aluminum Alloy
UPC	096359334408

Dimensions

Diameter - Inside	0.711 in
Weight	0.196 lb

Conductor Related

Conductor Compatibility	ACSR-Quail-2/0-6/1;ACSR- Pigeon-3/0-6/1;ACSR-Penguin- 4/0-6/1;ACSR-Waxwing-266.8- 18/1;ACSR-Partridge-266.8- 26/7;ACSR-Ostrich-300- 26/7;AAC-Aster-2/0-7;AAC- Phlox-3/0-7;AAC-Oxlip-4/0- 7;AAC-Valerian-250-19;AAC- Laurel-266.8-19;AAC-Tulip- 336.1-19;AAC-Daffodil-350- 19;AAAC 6201 Alloy-Anaheim- 155.4-6/18;AAAC 6201 Alloy- Amherst-195.7-6/18;AAAC 6201 Alloy-Alliance-246.9-6/18
-------------------------	---

Certifications And Compliance

UL Listed	Yes
-----------	-----

Logistics

Carton Quantity	48
-----------------	----

Product Assets

[Catalogs - Distribution Connectors](#)
[Installation Manuals - VACS Splice Installation Instructions](#)
[Sales Drawings - VACS_sales_drawing](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
AN-VACS350-SPEC-EN | REV 6/2024