


HUBBELL Power Systems

Compression Splice VERSAtile™ Minimum Tension

By ANDERSON
Catalog # [VACS400](#)

Minimum Tension versatile Compression Splice for 400 MCM str
AL/CU

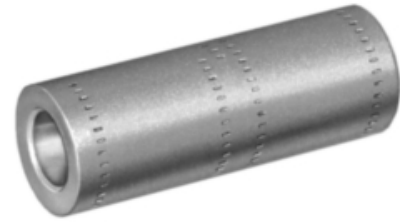

*Representative Image

Features

- For AL to AL, AL to CU connections
- AL9CU (90°C Rated)
- UL Listed
- CSA Certified

General

Catalog Number	VACS400
Color Code	Green
Compression Method	VersaCrimp or Conventional Die Tooling
Die Size	*See Resources / Downloads for die selection and installation instructions
EU RoHS Indicator	Contact Manufacturer
Material	Aluminum Alloy
UPC	096359334439

Dimensions

Diameter - Inside	0.758 in
Weight	0.294 lb

Conductor Related

Conductor Compatibility	ACSR-Pigeon-3/0-6/1;ACSR-Penguin-4/0-6/1;ACSR-Waxwing-266.8-18/1;ACSR-Partridge-266.8-26/7;ACSR-Ostrich-300-26/7;ACSR-Merlin-336.4-18/1;ACSR-Linnet-336.4-26/7;ACSR-Brahma-203.2-16/19;AAC-Phlox-3/0-7;AAC-Oxlip-4/0-7;AAC-Valerian-250-19;AAC-Laurel-266.8-19;AAC-Tulip-336.1-19;AAC-Daffodil-350-19;AAC-Canna-397.5-19;AAAC 6201 Alloy-Amherst-195.7-6/18;AAAC 6201 Alloy-Alliance-246.9-6/18
-------------------------	---

Certifications And Compliance

UL Listed	Yes
-----------	-----

Logistics

Carton Quantity	48
-----------------	----

Product Assets

[Catalogs - Distribution Connectors](#)
[Installation Manuals - VACS Splice Installation Instructions](#)
[Sales Drawings - VACS_sales_drawing](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
AN-VACS400-SPEC-EN | REV 6/2024