


Compression Splice VERSAtile™ Minimum Tension

By ANDERSON
Catalog # [VACS600](#)

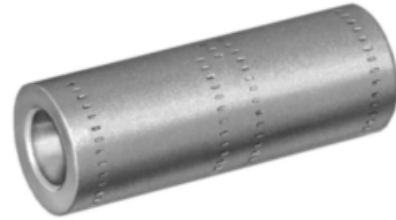

Minimum Tension versatile Compression Splice for 600 MCM str AL

*Representative Image

Features

- For AL to AL, AL to CU connections
- AL9CU (90°C Rated)
- UL Listed
- CSA Certified

General

Color Code	Pink
Compression Method	VersaCrimp or Conventional Die Tooling
Die Size	*See Resources / Downloads for die selection and installation instructions
EU RoHS Indicator	Contact Manufacturer
Material	Aluminum Alloy
UPC	096359334460

Dimensions

Diameter - Inside	0.923 in
Weight	0.490 lb

Conductor Related

Conductor Compatibility	ACSR-Ostrich-300-26/7;ACSR-Merlin-336.4-18/1;ACSR-Linnet-336.4-26/7;ACSR-Oriole-336.4-30/7;ACSR-Chickadee-397.5-18/1;ACSR-Brant-397.5-24/7;ACSR-Ibis-397.5-26/7;ACSR-Lark-397.5-30/7;ACSR-Pelican-477-18/1;ACSR-Flicker-477-24/7;ACSR-Hawk-477-26/7;ACSR-Hen-477-30/7;ACSR-Osprey-556.5-18/1;ACSR-Brahma-203.2-16/19;AAC-Daffodil-350-19;AAC-Canna-397.5-19;AAC-Cosmos-477-19;AAC-Syringa-477-37;AAC-Zinnia-500-19;AAC-Hyacinth-500-37;AAC-Dahlia-556.5-19;AAC-Mistletoe-556.5-37;AAC-Meadowsweet-600-37
-------------------------	--

Certifications and Compliance

UL Listed	Yes
-----------	-----

Logistics

Carton Quantity	24
-----------------	----

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Installation Manuals - VACS Splice Installation Instructions](#)
[Sales Drawings - VACS_sales_drawing](#)