

Compression Splice

VERSA-CRIMP®


Full Tension

By ANDERSON

Catalog # [VC410A](#)

Full Tension VersaCrimp Aluminum Compression Splice for AL

#4 (7), #2 (7), 1/0 (7)

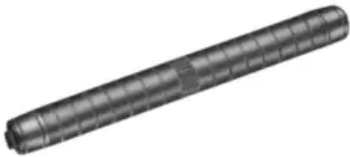

\*Representative Image

Features

- VERSA-CRIMP tools only
- One piece design eliminates cutting strands on ACSR
- Can be used with compressed (compact) conductor sizes within the same decimal range

General

Catalog Number	VC410A
Compression Method	VersaCrimp Tooling ONLY VC6-3, VC6FT or VC8
EU RoHS Indicator	Contact Manufacturer
Material	Aluminum Alloy
UPC	096359364979

Dimensions

Length Before Compression	6.25 in
---------------------------	---------

Conductor Related

Conductor Diameter (VersaCrimp) - Maximum	0.232 in
Conductor Diameter (VersaCrimp) - Minimum	0.368 in

Certifications And Compliance

Buy America(n) Qualified	TAA Compliant (All status valid till December 2024)
UL Listed	No

Logistics

Carton Quantity	100
-----------------	-----

Product Assets

[Sales Drawings - VC410A\\_drawing](#)

[Specifications - VC410A](#)