


Compression Stirrup

By ANDERSON
Catalog # [VCLSC5021](#)

VersaCrimp Copper Overhead Compression Stirrup

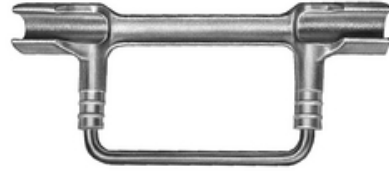

*Representative Image

Features

- For use with VersaCrimp tools only (VC6 and VC7 series).

General

EU RoHS Indicator	No
Material	Copper
Material - Body	Cast Copper Alloy
Material - Stirrup	Copper
Plating	No
Type	Stirrups
UPC	096359336976

Dimensions

Copper Loop Size	0.325 in
Diameter - Stirrup Nominal Wire	1/0 Solid
Weight	0.980 lb
Width - Main Contact	5 in

Conductor Related

Conductor Diameter - Maximum	0.419
Conductor Diameter - Minimum	0.258
Conductor Diameter Range	0.258 - 0.419

Logistics

Carton Quantity	40
Packaging Type	Box

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)