


HUBBELL Power Systems

Compression Splice VERSAtile™ Minimum Tension

By ANDERSON
Catalog # [VHS1](#)

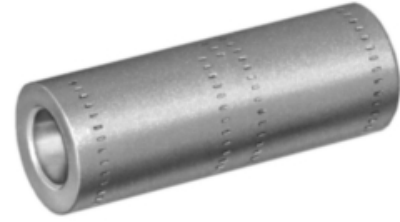

Copper long barrel Versatile splice, #1 STR

*Representative Image

Features

For use with VersaCrimp or conventional die type tooling.

General

| | |
|--------------------|--|
| Application | Power Connector |
| Catalog Number | VHS1 |
| Color Code | Green |
| Compression Method | VersaCrimp or Conventional Die Tooling |
| Die Size | VC6 (all), VC7 (all) |
| EU RoHS Indicator | Contact Manufacturer |
| Inhibitor Loaded | No |
| Material | Copper |
| Trade Name | NO |
| UPC | 096359338833 |
| UPC 12 Digit | 096359338833 |

Dimensions

| | |
|---------------------------|----------|
| Length Before Compression | 2.88 in |
| Weight | 0.098 lb |

Electrical Ratings

| | |
|--------------|-------|
| Rating - KVA | 35 kV |
|--------------|-------|

Conductor Related

| | |
|---|----------|
| Conductor Diameter (Conventional Tooling) - Maximum | 0.332 in |
| Conductor Diameter (Conventional Tooling) - Minimum | 0.328 in |
| Conductor Diameter (VersaCrimp) - Maximum | 0.332 in |
| Conductor Diameter (VersaCrimp) - Minimum | 0.184 in |

Certifications And Compliance

| | |
|------------------------------------|-----|
| Certification - CSA Approved | Yes |
| Standards - RoHS Compliance Status | UI |
| UL Listed | Yes |

Logistics

| | |
|-----------------|------|
| Carton Quantity | 90 |
| Pallet Quantity | 9600 |

Product Assets

[Catalogs - Distribution Connectors](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - 50025089](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
AN-VHS1-SPEC-EN | REV 6/2024