


Compression Splice VERSAtile™ Minimum Tension

By ANDERSON
Catalog # VHS10

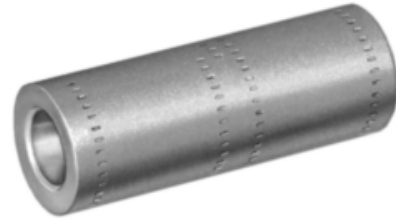

Copper long barrel Versatile splice 1/0 Str.

*Representative Image

Features

- For use with VersaCrimp or conventional die type tooling.

Application

Power Connector

General

Color Code	Pink
Compression Method	VersaCrimp or Conventional Die Tooling
Die Size	VC6 (all), VC7 (all)
EU RoHS Indicator	Contact Manufacturer
Inhibitor Loaded	No
Material	Copper
Trade Name	NO
UPC	096359338840
UPC 12 Digit	096359338840

Dimensions

Length Before Compression	2.88 in
Weight	0.098 lb

Electrical Ratings

Rating - KVA	35 kV
--------------	-------

Conductor Related

Conductor Diameter (Conventional Tooling) - Maximum	0.373 in
Conductor Diameter (Conventional Tooling) - Minimum	0.368 in
Conductor Diameter (VersaCrimp) - Maximum	0.373 in
Conductor Diameter (VersaCrimp) - Minimum	0.184 in

Certifications and Compliance

Certification - CSA Approved	Yes
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	90
Pallet Quantity	6480

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - 50025089](#)