


HUBBELL Power Systems

Compression Splice VERSAtile™ Minimum Tension

By ANDERSON
Catalog # [VHS30](#)

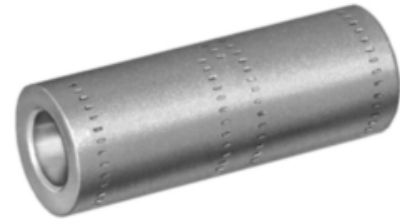

Copper long barrel Versatile splice, LNG BARREL 3/0 STR

*Representative Image

Features

For use with VersaCrimp or conventional die type tooling.

General

Application	Power Connector
Catalog Number	VHS30
Color Code	Orange
Compression Method	VersaCrimp or Conventional Die Tooling
Die Size	VC6 (all), VC7 (all)
EU RoHS Indicator	Contact Manufacturer
Inhibitor Loaded	No
Material	Copper
Trade Name	NO
UPC	096359338918
UPC 12 Digit	096359338918

Dimensions

Length Before Compression	3.12 in
Weight	0.098 lb

Electrical Ratings

Rating - KVA	35 kV
--------------	-------

Conductor Related

Conductor Diameter (Conventional Tooling) - Maximum	0.528 in
Conductor Diameter (Conventional Tooling) - Minimum	0.464 in
Conductor Diameter (VersaCrimp) - Maximum	0.47 in
Conductor Diameter (VersaCrimp) - Minimum	0.292 in

Certifications And Compliance

Certification - CSA Approved	Yes
Standards - RoHS Compliance Status	EX
UL Listed	Yes

Logistics

Carton Quantity	90
Pallet Quantity	9600

Product Assets

[Catalogs - Distribution Connectors](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - 50025089](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
AN-VHS30-SPEC-EN | REV 6/2024