


# HUBBELL Power Systems

## Compression Splice VERSAtile™ Minimum Tension

By ANDERSON  
Catalog # [VHSS20](#)

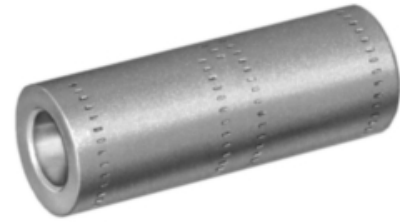

Copper short barrel Versatile splice, 2/0 STR

\*Representative Image

### Features

For use with VersaCrimp or conventional die type tooling.

### General

Application	Power Connector
Catalog Number	VHSS20
Color Code	Black
Compression Method	VersaCrimp or Conventional Die Tooling
Die Size	VC6 (all), VC7 (all)
EU RoHS Indicator	Contact Manufacturer
Inhibitor Loaded	No
Material	Copper
Trade Name	NO
UPC	096359339045
UPC 12 Digit	096359339045

### Dimensions

Length Before Compression	2 in
Weight	0.098 lb

### Electrical Ratings

Rating - KVA	35 kV
--------------	-------

### Conductor Related

Conductor Diameter (Conventional Tooling) - Maximum	0.419 in
Conductor Diameter (Conventional Tooling) - Minimum	0.414 in
Conductor Diameter (VersaCrimp) - Maximum	0.419 in
Conductor Diameter (VersaCrimp) - Minimum	0.232 in

### Certifications And Compliance

Standards - RoHS Compliance Status	EX
UL Listed	Yes

### Logistics

Carton Quantity	90
-----------------	----

### Product Assets

[Catalogs - Distribution Connectors](#)  
[Customer Notices - Prop 65 Notice](#)



**A Hubbell brand**

©2024 Hubbell Incorporated. All rights reserved  
AN-VHSS20-SPEC-EN | REV 6/2024