


Compression Splice VERSAtile™ Minimum Tension

By ANDERSON
Catalog # [VHSS350](#)

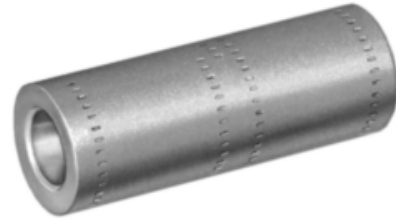

Copper short barrel Versatile splice, 350 MCM

*Representative Image

Features

- For use with VersaCrimp or conventional die type tooling.

Application

Power Connector

General

Color Code	Red
Compression Method	VersaCrimp or Conventional Die Tooling
Die Size	VC6-3, VC6FT, VC7, VC7FT
EU RoHS Indicator	Contact Manufacturer
Inhibitor Loaded	No
Material	Copper
Trade Name	NO
UPC	096359339076
UPC 12 Digit	096359339076

Dimensions

Length Before Compression	2.38 in
Weight	0.196 lb

Electrical Ratings

Rating - KVA	35 kV
--------------	-------

Conductor Related

Conductor Diameter (Conventional Tooling) - Maximum	0.675 in
Conductor Diameter (Conventional Tooling) - Minimum	0.675 in
Conductor Diameter (VersaCrimp) - Maximum	0.675 in
Conductor Diameter (VersaCrimp) - Minimum	0.464 in

Certifications and Compliance

Standards - RoHS Compliance Status	EX
UL Listed	Yes

Logistics

Carton Quantity	54
Pallet Quantity	5760

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Customer Notices - Prop 65 Notice](#)