


Compression Splice VERSAtile™ Minimum Tension

By ANDERSON
Catalog # VHSS40

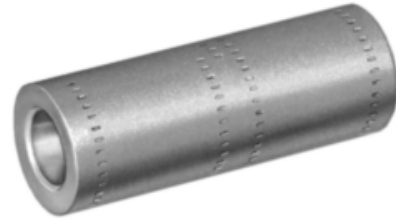

Copper short barrel Versatile splice, 4/0 STR

*Representative Image

Features

- For use with VersaCrimp or conventional die type tooling.

Application

Power Connector

General

Color Code	Purple
Compression Method	VersaCrimp or Conventional Die Tooling
Die Size	VC6 (all), VC7 (all)
EU RoHS Indicator	Contact Manufacturer
Inhibitor Loaded	No
Material	Copper
Trade Name	NO
UPC	096359339090
UPC 12 Digit	096359339090

Dimensions

Length Before Compression	2.12 in
Weight	0.098 lb

Electrical Ratings

Rating - KVA	35 kV
--------------	-------

Conductor Related

Conductor Diameter (Conventional Tooling) - Maximum	0.528 in
Conductor Diameter (Conventional Tooling) - Minimum	0.522 in
Conductor Diameter (VersaCrimp) - Maximum	0.528 in
Conductor Diameter (VersaCrimp) - Minimum	0.328 in

Certifications and Compliance

Standards - RoHS Compliance Status	EX
UL Listed	Yes

Logistics

Carton Quantity	90
Pallet Quantity	6480

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Customer Notices - Prop 65 Notice](#)