


## Compression Splice VERSAtile™ Minimum Tension

By ANDERSON  
Catalog # VHSS750

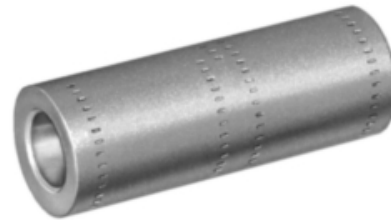

Copper short barrel Versatile splice, 750 MCM

\*Representative Image

### Features

- For use with VersaCrimp or conventional die type tooling.

### Application

Power Connector

### General

Color Code	Black
Compression Method	VersaCrimp or Conventional Die Tooling
Die Size	VC6FT, VC7FT or VC8
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Trade Name	NO
UPC	096359339144
UPC 12 Digit	0096359339142

### Dimensions

Length Before Compression	3.38 in
Weight	0.490 lb

### Electrical Ratings

Rating - KVA	35 kV
--------------	-------

### Conductor Related

Conductor Diameter (Conventional Tooling) - Maximum	0.998 in
Conductor Diameter (Conventional Tooling) - Minimum	0.998 in
Conductor Diameter (VersaCrimp) - Maximum	0.998 in
Conductor Diameter (VersaCrimp) - Minimum	0.811 in

### Certifications and Compliance

Standards - RoHS Compliance Status	EX
UL Listed	Yes

### Logistics

Carton Quantity	27
Pallet Quantity	1500

### Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)  
[Customer Notices - Prop 65 Notice](#)