


# HUBBELL

## Power Systems

### Yoke Plate, Rectangular

By ANDERSON  
Catalog # [YPR30173512](#)

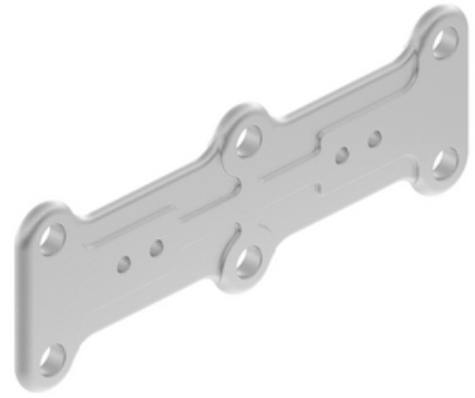

These yoke plates are used with a double string of insulators to deadend a two conductor bundle. Type YPR yoke plates may be furnished in a variety of sizes, hole spacings, ultimate strengths and provisions for mounting corona rings. Material: body - galvanized ductile iron or galvanized steel.

#### Features

Type YPR yoke plates may be furnished in a variety of sizes, hole spacings, ultimate strengths and provisions for mounting corona rings. Material: body - galvanized ductile iron or galvanized steel

#### General

Corona Ring Mounting Provision	4 x 0.563" holes
EU RoHS Indicator	No
Material	Ductile Iron
Number of Bolt Holes	0
Series	YPR Series
Strength Rating - Ultimate	30000 lb
Strength Rating - Ultimate Body	0 lb
UPC	096359345251

#### Dimensions

Assembly Rating (Ultimate)	0 lb
Diameter - Bolt	0 in
Diameter - Insulator Attachment Holes	1.125 in
Diameter - Pin	0 in
Insulator / Conductor Hole Spacing	18 in
Insulator Throat Diameter - Maximum	0 in
Insulator Throat Diameter - Minimum	0 in
Length - Coupling	4.5 in
Length - Pin	0 in
Maximum Adjustment	0 in
Ring Height	0 in
Thickness	0.75 in
Weight	15.68 lb

#### Conductor Related

Conductor Diameter - Maximum	0 in
Conductor Spacing Diameter - Conductor Attachment Holes	0 in 1.125 in

#### Product Assets

[Catalogs - Transmission Connectors Catalog - Full](#)



**A Hubbell brand**

©2024 Hubbell Incorporated. All rights reserved  
AN-YPR30173512-SPEC-EN | REV 6/2024