



2.4/5/6 GHZ 5/7/7 DBI 1 ELEMENT INDOOR/OUTDOOR OMNI ANTENNA WITH N-STYLE PLUG (WHITE) ATS-04010 (ATS-OO-2456-577-1NP-IC-W)



ELECTRICAL SPECIFICATIONS

Frequency Range: 2.4-2.5/5.15-5.85/5.925-7.125 GHz
 Gain: 5/7/7dBi
 Polarization: Vertical
 Horizontal Beamwidth: 360°
 Vertical Beamwidth: 60°
 VSWR: <1.5:1 Max: 2.0
 Isolation: >20dB
 Impedance: 50 Ω



MECHANICAL SPECIFICATIONS

Dimensions: 10.77" x Ø.94" (273.6 x Ø23.8mm)
 Radome Material: ASA
 Number of Elements: 1

Color: White
 Connector: N-Style Plug



ENVIRONMENTAL SPECIFICATIONS

Installation Environment: Indoor or Outdoor
 IP Rating: IP66



WARRANTY

2 Year Limited Warranty



VERTICAL

HORIZONTAL

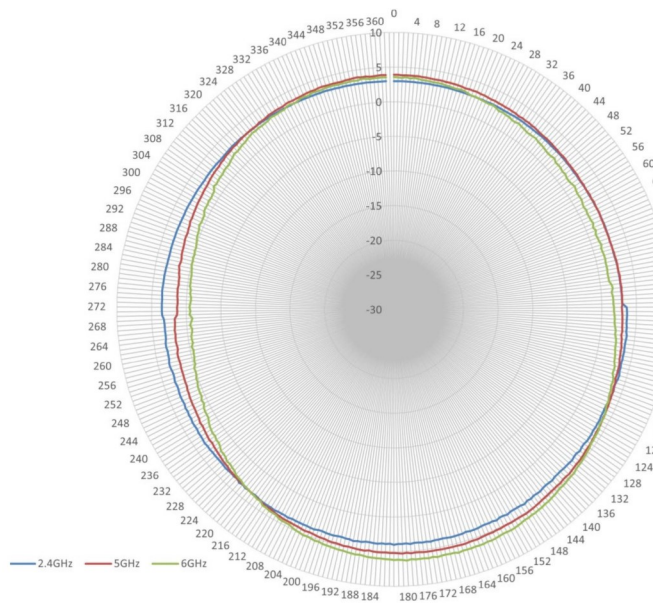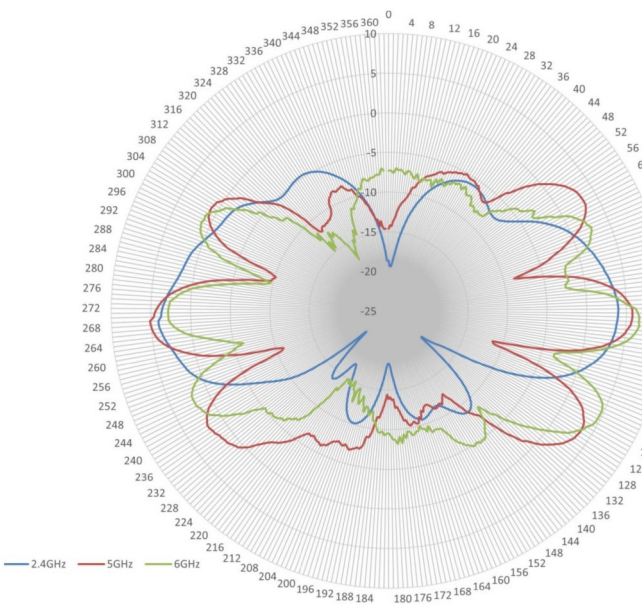



2.4/5/6 GHZ 5/7/7 DBI 1 ELEMENT INDOOR/OUTDOOR OMNI ANTENNA WITH N-STYLE PLUG (WHITE) ATS-04010 (ATS-OO-2456-577-1NP-IC-W)

