



2.4/5/6 GHZ 4/5/6 DBI 1 ELEMENT INDOOR OMNI ANTENNA WITH RPSMA PLUG ATS-04012 (ATS-ID90RD-2456-456-1RPSP-IC-W)



ELECTRICAL SPECIFICATIONS

Frequency Range: 2.4-2.5/5.15-5.85/5.925-7.125 GHz
Gain: 4/5/6dBi
Polarization: Vertical
Horizontal Beamwidth: 360°
Vertical Beamwidth: 100°
VSWR: <1.5:1 Max: 2.0
Isolation: >20dB
Impedance: 50 Ω



MECHANICAL SPECIFICATIONS

Dimensions: 4.9" x Ø.94" (125 x Ø24mm)
Radome Material: ASA
Number of Elements: 1

Color: White
Connector: RPSMA Plug



ENVIRONMENTAL SPECIFICATIONS

Installation Environment: Indoor or Outdoor
IP Rating: IP66



WARRANTY

2 Year Limited Warranty



VERTICAL

HORIZONTAL

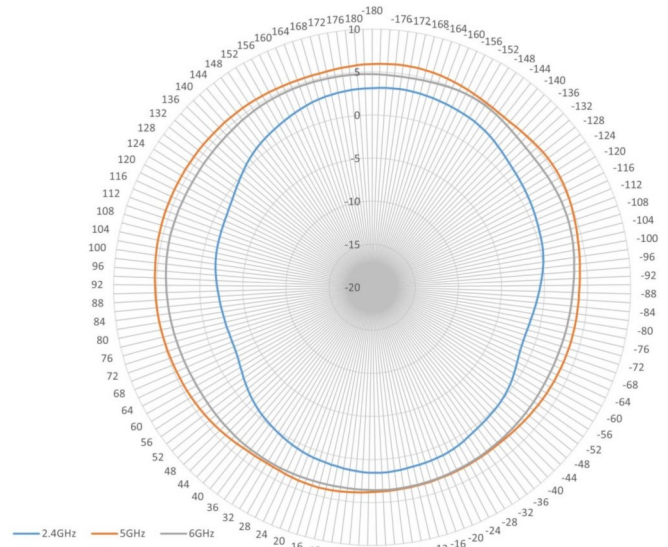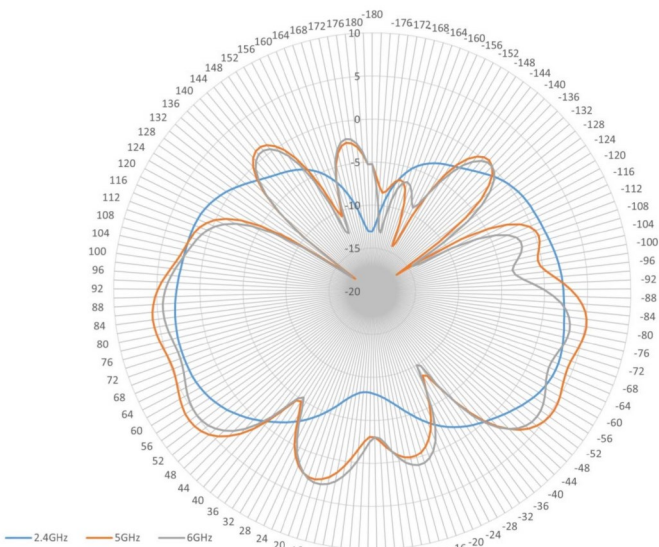



2.4/5/6 GHZ 4/5/6 DBI 1 ELEMENT INDOOR OMNI
ANTENNA WITH RPSMA PLUG
ATS-04012 (ATS-ID90RD-2456-456-1RPSP-IC-W)

