



2.4/5/6 GHZ 3/4/4 DBI 6 ELEMENT INDOOR/OUTDOOR OMNI ANTENNA WITH RPSMA PLUG ATS-04119 (ATS-OO-2456-344-6RPSP-36)



ELECTRICAL SPECIFICATIONS

Frequency Range: 2.4-2.5/5.15-5.85/5.925-7.125
GHz Gain: 3/4/4 dBi
Polarization: Vertical
Horizontal Beamwidth: 360°
Vertical Beamwidth: 70°
VSWR: <1.5:1 Max: 2.0
Isolation: >20dB
Impedance: 50 Ω



MECHANICAL SPECIFICATIONS

Dimensions: 5.8" x 5.8" x 1.5" (150mm x 150mm x 40mm)
Radome Material: ASA
Connector: RPSMA Plug

Cable: ATS-200
Cable Length: 36" (915mm)
Number of Elements: 6



ENVIRONMENTAL SPECIFICATIONS


Installation Environment: Indoor or Outdoor
IP Rating: IP66

WARRANTY


2 Year Limited Warranty



VERTICAL

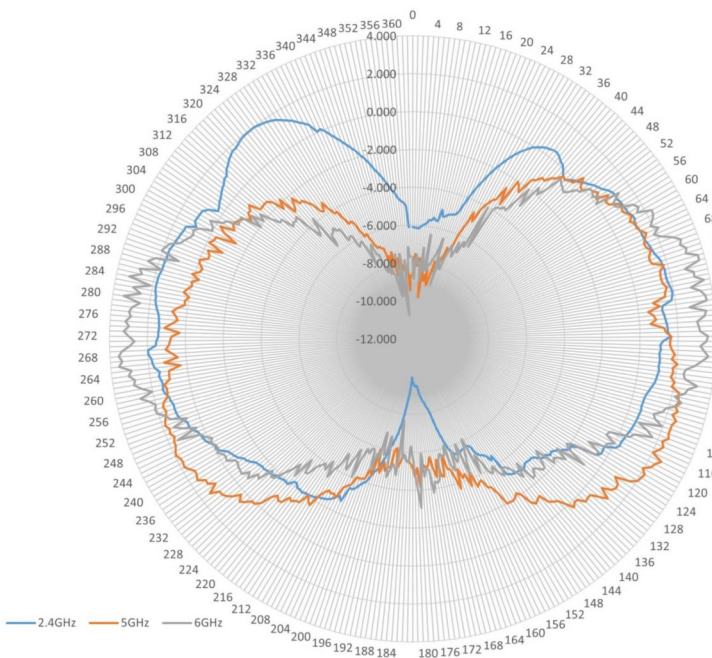

HORIZONTAL

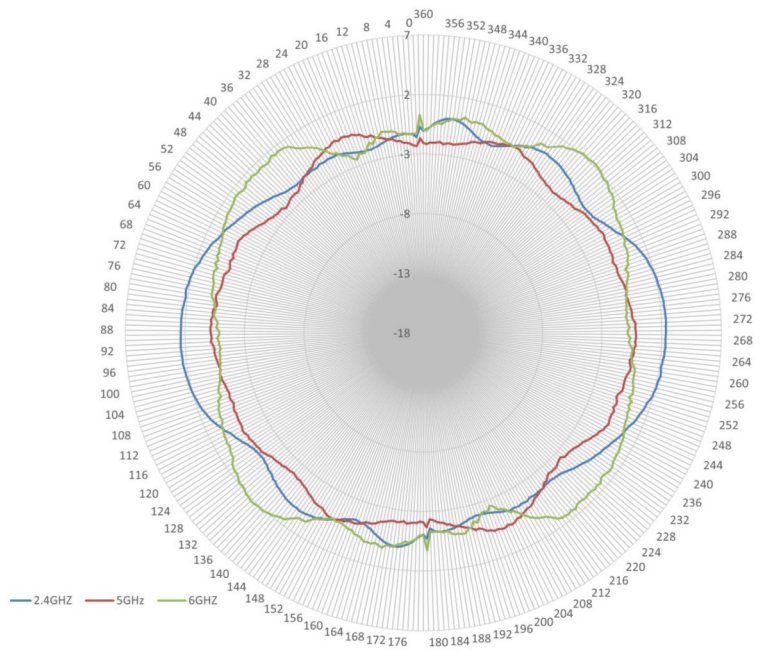



2.4/5/6 GHZ 3/4/4 DBI 6 ELEMENT INDOOR/OUTDOOR OMNI ANTENNA WITH RPSMA PLUG ATS-04119 (ATS-OO-2456-344-6RPSP-36)

