



# 2.4/5/6 GHZ 3/4/4 DBI 6 ELEMENT INDOOR/OUTDOOR OMNI ANTENNA WITH N-STYLE PLUG ATS-04121 (ATS-OO-2456-344-6NP-36)



## ELECTRICAL SPECIFICATIONS

Frequency Range: 2.4-2.5/5.15-5.85/5.925-7.125 GHz  
Gain: 3/3/3dBi  
Polarization: Vertical  
Horizontal Beamwidth: 360°  
Vertical Beamwidth: 70°  
VSWR: <1.5:1 Max: 2.0  
Isolation: >20dB  
Impedance: 50 Ω



## MECHANICAL SPECIFICATIONS

Dimensions: 5.8" x 5.8" x 1.5" (150mm x 150mm x 40mm)  
Radome Material: ASA  
Connector: N-Style Plug

Cable: ATS-200  
Cable Length: 36" (915mm)  
Number of Elements: 6



## ENVIRONMENTAL SPECIFICATIONS


Installation Environment: Indoor or Outdoor  
IP Rating: IP66

## WARRANTY


2 Year Limited Warranty



## VERTICAL

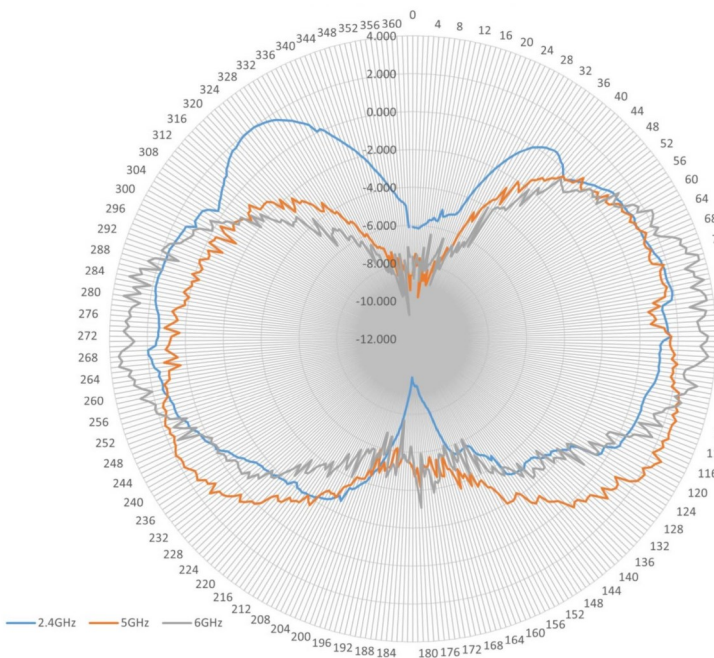

## HORIZONTAL

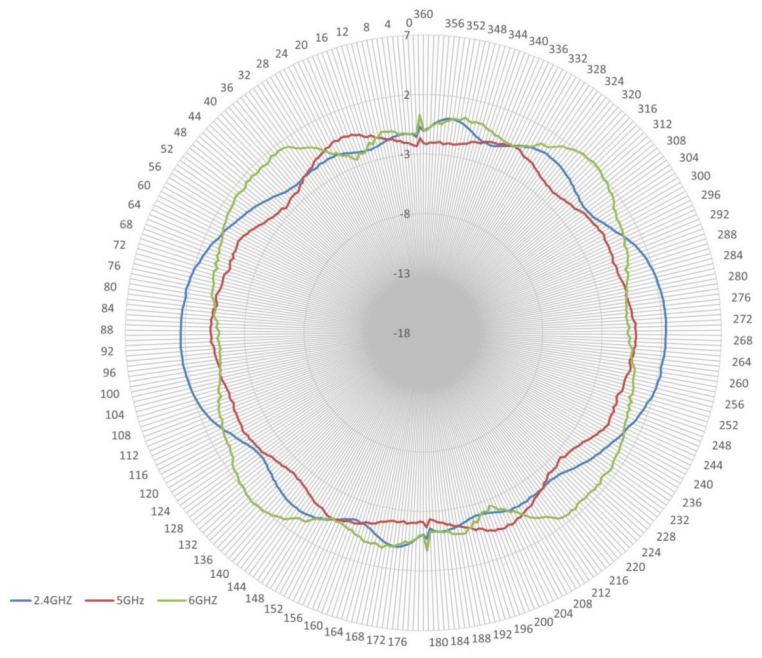



# 2.4/5/6 GHZ 3/4/4 DBI 6 ELEMENT INDOOR/OUTDOOR OMNI ANTENNA WITH N-STYLE PLUG ATS-04121 (ATS-OO-2456-344-6NP-36)

