



# 2.4/5/6 GHZ 7 DBI 4 ELEMENT INDOOR/OUTDOOR PATCH ANTENNA WITH N-STYLE PLUGS ATS-04153 (ATS-OP-2456-7-4NP-36)



## ELECTRICAL SPECIFICATIONS

Frequency Range: 2.4-2.48/5.15-5.85/6-7.125 GHz  
 Gain: 6/7/7dBi  
 Polarization: Vertical  
 Horizontal Beamwidth: 120°/105°/105°  
 Vertical Beamwidth: 45°/55°/50°  
 VSWR: <1.5:1 Max: 2.0  
 Isolation: >30dB  
 Impedance: 50 Ω



## MECHANICAL SPECIFICATIONS

Dimensions: 15.4" x 15.4" x 2.24" (390x390x57mm)  
 Weight: 2.5 (0.68 kg)  
 Installation: Flush Mount to Wall or Articulating  
 Wall/Pole Mount (Included)  
 Cable Type: ATS-195

Radome Material: ASA  
 Connector: 4 N-Style Plug  
 Number of Leads: 4  
 Cable Length: 36" (910mm)



## ENVIRONMENTAL SPECIFICATIONS


Installation Environment: Indoor Only due to LPI requirements  
 IP Rating: IP67

## WARRANTY


2 Year Limited Warranty



## VERTICAL

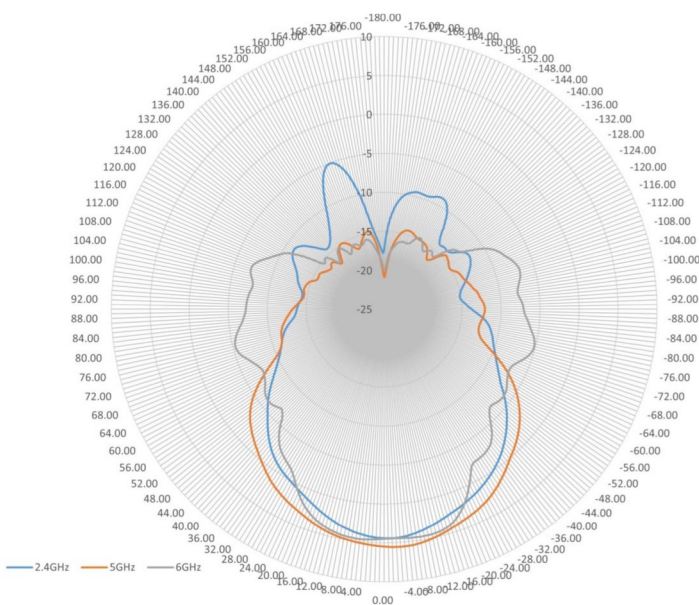

## HORIZONTAL

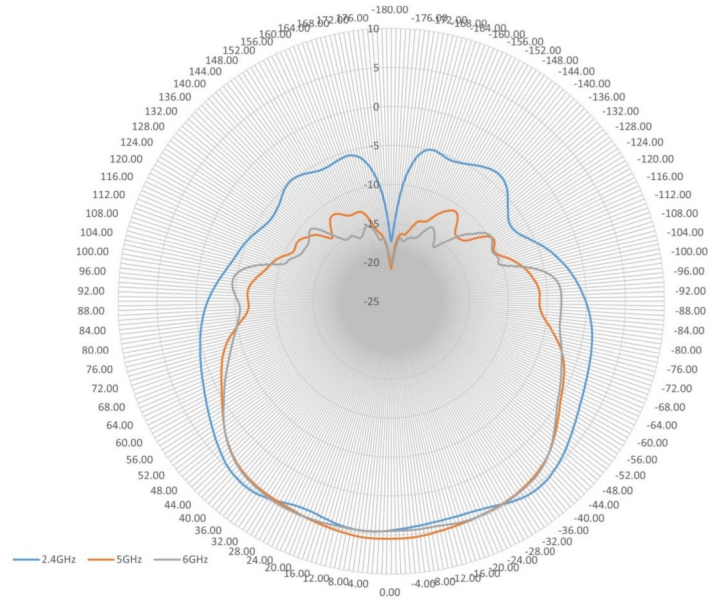



# 2.4/5/6 GHZ 7 DBI 4 ELEMENT INDOOR/OUTDOOR PATCH ANTENNA WITH N-STYLE PLUGS ATS-04153 (ATS-OP-2456-7-4NP-36)

