



The AccelTex Solutions dual band indoor rubber duck antenna is a perfect complement to any enterprise-class AP to achieve desired coverage in your indoor space. The antenna element is optimized for Wi-Fi operation on both 2.4 and 5 GHz. This antenna also articulates 90 degrees and attaches directly to any enterprise-class AP. This highly versatile antenna is suitable for a broad range of indoor applications where a higher gain external antenna is not needed.

Part Number: ATS-ID90RD-245-23-1RSP-IC-W

> ELECTRICAL SPECIFICATIONS

Frequency Range: 2.4-2.5/4.9-5.85 GHz
 Gain: 2/3 dBi
 Polarization: Vertical
 Horizontal Beamwidth: 360°

VSWR: Max 2.0
 Impedance: 50 Ω

> MECHANICAL SPECIFICATIONS

Dimensions: ϕ 0.51" x 5.14" L (ϕ 13mm x 130.5mm L)
 Connector: RPSMA Plug
 Installation: Direct Connect to AP
 Color: White

Articulation: 90 Degrees


> ENVIRONMENTAL SPECIFICATIONS

Installation Environment: Indoor
 IP Rating: IP66

> WARRANTY

2 Year Limited Warranty

> 2.45 GHZ

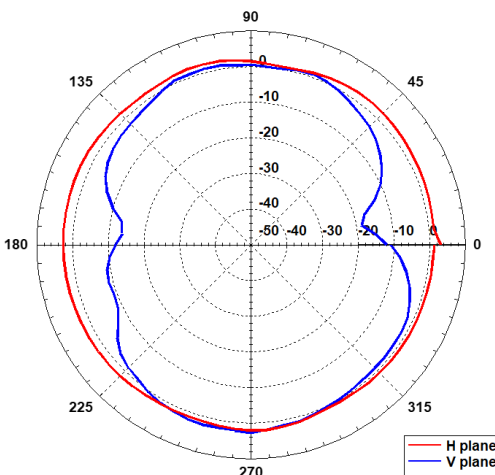

> 5.5 GHZ

