



ELECTRICAL SPECIFICATIONS

Frequency Range: 2.4-2.5/4.9-5.85 GHz
Gain: 4 / 4 dBi
Polarization: 2 Horizontal –2 Vertical
Horizontal Beamwidth: 90°/90°
Vertical Beamwidth: 90°/90°
VSWR: < 2



MECHANICAL SPECIFICATIONS

Dimensions: 11" x 5.9" x 1.97" (280x150x50mm)
Weight: 2.2 lb (0.99 kg)
Mounting: Threaded Center Bolt w/ Nut
& Articulating Wall/Pole Mount (included)
Installation Hole Diameter: 1" (25mm)
Pole Mount Diameter: 2" (508mm)

Radome Material: ASA
Connector: RPTNC
Number of Leads: 4
Cable Length: 36" (910 mm)
Cable Type: ATS-195



ENVIRONMENTAL SPECIFICATIONS


Installation Environment: Indoor/Outdoor
Operating Temperature: -40 to 149°F (-40 to 65°C)
Wind Velocity: 130 mph (209 km/h)
IP Rating: IP66

WARRANTY

2 Year Limited Warranty



HORIZONTAL

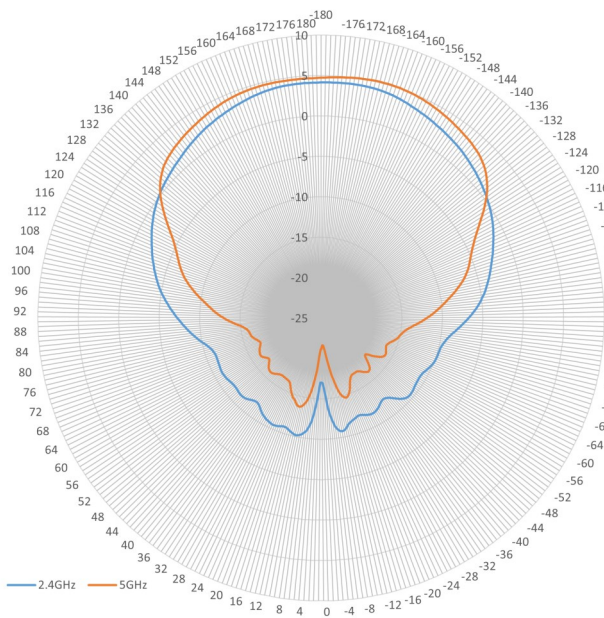

VERTICAL

